



Brand of NTN Group

Technical data

ESSP207

Bearing units




Grey cast housing, radial insert ball bearing with eccentric locking collar, single lip seal

KIT CONTENT

ES207G2, SP206-207/72

VISUAL (S)

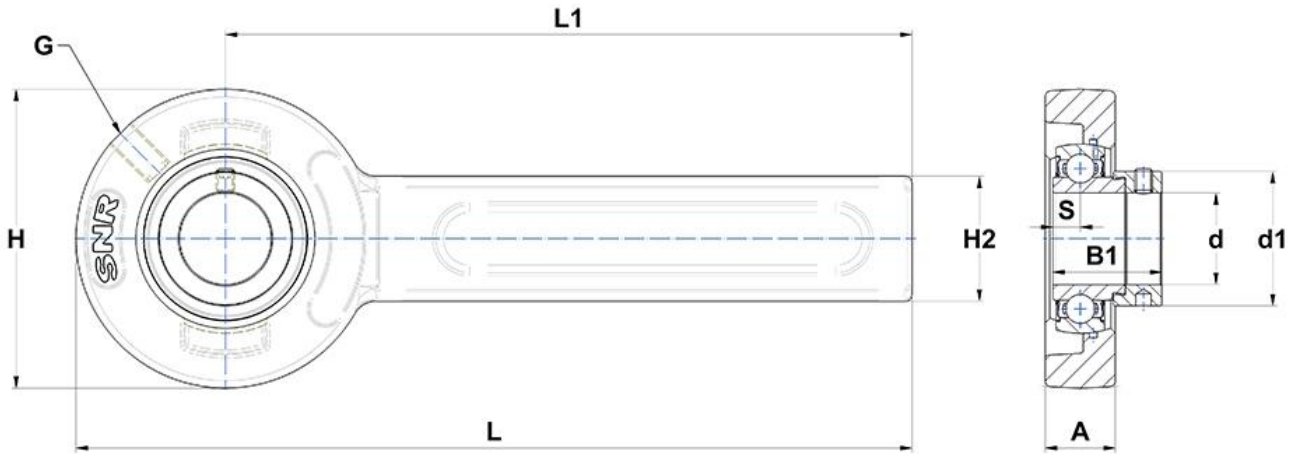

PRODUCT DEFINITION

Brand	SNR
A - Housing width	21 mm
B1 - Overall width Inner Ring	38,9 mm
d - Shaft diameter	35 mm
d1 - Outer dia of eccent. Lock. collar / nut of adapter sleeve	51,1 mm
G - Grease fitting	R1/8"



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

H - Housing length, width or diameter	98 mm
H2 - Housing height / width	41 mm
L - Housing length	274 mm
L1 - Distance attachment end face to bearing centerline	225 mm
S - Distance front side/bearing centre	9,5 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	25700000 mN
C0 - Static load rating	15200000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Stretcher frame 2	SPR11
Stretcher frame 3	SPR12
Stretcher frame 4	SPR14
Mass	1,96 kg
Recommended tightening torque for set screw	11.5 N-m

