

RC-12P1N8A0000 - Contact insert

1597464

<https://www.phoenixcontact.com/in/products/1597464>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Contact insert, M23, number of positions: 12, contact connection type: Pin, Crimp connection, series: NC, RC, RM, TU, UC

Commercial data

Item number	1597464
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	ABR
Product key	ABRAFT
GTIN	4046356216173
Weight per piece (including packing)	1.66 g
Weight per piece (excluding packing)	1.54 g
Customs tariff number	85389099
Country of origin	DE

RC-12P1N8A0000 - Contact insert



1597464

<https://www.phoenixcontact.com/in/products/1597464>

Technical data

Notes

Order information:	Order crimp contacts Ø 1 mm separately
--------------------	--

Product properties

Product type	Contact insert
Series	NC
	RC
	RM
	TU
	UC
Application	Signal
Number of positions	12
Connection profile	12
Coding	N
Thread type	M23

Electrical properties

Contact	
Contact diameter	1 mm
Max. current	8 A
Nominal voltage U _N	48 V AC 74 V DC
Overvoltage category	III
Degree of pollution	3
Rated surge voltage	1.5 kV

Connection data

Connection method	Crimp connection
-------------------	------------------

Material specifications

Insulator material	PA66
--------------------	------

Connector

Direction of rotation	Standard
-----------------------	----------

Environmental and real-life conditions

Ambient conditions	
Ambient temperature (storage/transport)	15 °C ... 25 °C
Permissible humidity (storage/transport)	50 % ... 65 %

RC-12P1N8A0000 - Contact insert


1597464

<https://www.phoenixcontact.com/in/products/1597464>



Drawings

Schematic diagram

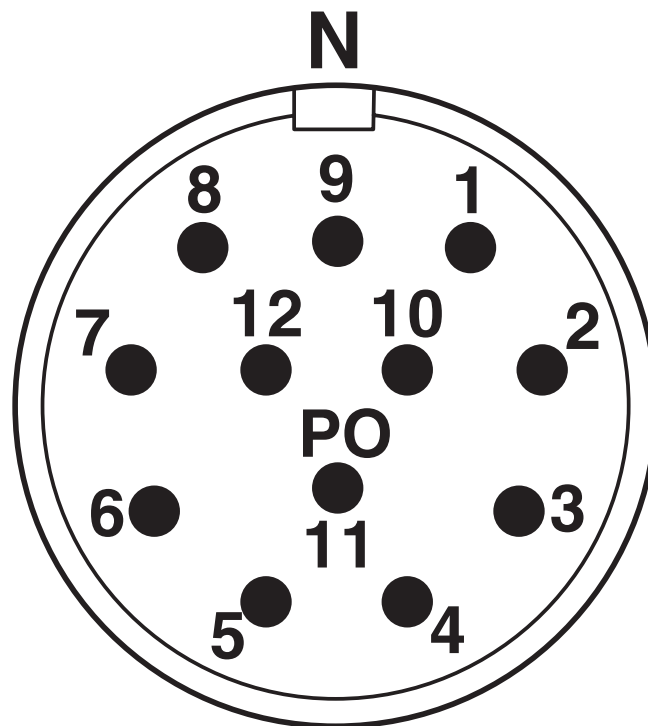

Connector pin assignment

RC-12P1N8A0000 - Contact insert



1597464

<https://www.phoenixcontact.com/in/products/1597464>

Classifications

ECLASS

ECLASS-13.0	27440223
-------------	----------

ETIM

ETIM 9.0	EC003557
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

RC-12P1N8A0000 - Contact insert



1597464

<https://www.phoenixcontact.com/in/products/1597464>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

RC-12P1N8A0000 - Contact insert

1597464

<https://www.phoenixcontact.com/in/products/1597464>



Accessories

RC-11P2000 - Crimp contact

1596770

<https://www.phoenixcontact.com/in/products/1596770>



Crimp contact, Pin, turned, Single contact, contact diameter: 1 mm, crimp range: 0.08 mm² ... 0.22 mm², Contact release tool not necessary for the 12- and 17-pos. crimp versions of the M23-PRO series, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1240882

RC-12P2000 - Crimp contact

1597862

<https://www.phoenixcontact.com/in/products/1597862>



Crimp contact, Pin, turned, Single contact, contact diameter: 1 mm, crimp range: 0.14 mm² ... 0.56 mm², Contact release tool not necessary for the 12- and 17-pos. crimp versions of the M23-PRO series, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1240882

RC-12P1N8A0000 - Contact insert

1597464

<https://www.phoenixcontact.com/in/products/1597464>



RC-1KP2000 - Crimp contact

1602996

<https://www.phoenixcontact.com/in/products/1602996>



Crimp contact, Pin, turned, Single contact, contact diameter: 1 mm, crimp range: 0.5 mm² ... 1 mm², Contact release tool not necessary for the 12- and 17-pos. crimp versions of the M23-PRO series, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1241571

RC-22P2000 - Crimp contact

1603321

<https://www.phoenixcontact.com/in/products/1603321>



Crimp contact, Pin, rolled, Single contact, contact diameter: 1 mm, crimp range: 0.22 mm² ... 0.56 mm², Single contact, Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

RC-12P1N8A0000 - Contact insert

1597464

<https://www.phoenixcontact.com/in/products/1597464>



RC-22P2300 - Crimp contact

1603324

<https://www.phoenixcontact.com/in/products/1603324>



Crimp contact, Pin, rolled, Taped product, number of pieces per reel: 500, contact diameter: 1 mm, crimp range: 0.22 mm² ... 0.56 mm², Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

RC-22P2400 - Crimp contact

1603325

<https://www.phoenixcontact.com/in/products/1603325>



Crimp contact, Pin, rolled, Taped product, number of pieces per reel: 10000, contact diameter: 1 mm, crimp range: 0.22 mm² ... 0.56 mm², Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

RC-12P1N8A0000 - Contact insert

1597464

<https://www.phoenixcontact.com/in/products/1597464>



RC-21P2000 - Crimp contact

1603310

<https://www.phoenixcontact.com/in/products/1603310>



Crimp contact, Pin, rolled, Single contact, contact diameter: 1 mm, crimp range: 0.08 mm² ... 0.22 mm², Single contact

RC-21P2300 - Crimp contact

1603313

<https://www.phoenixcontact.com/in/products/1603313>



Crimp contact, Pin, rolled, Taped product, number of pieces per reel: 500, contact diameter: 1 mm, crimp range: 0.08 mm² ... 0.22 mm²

RC-12P1N8A0000 - Contact insert

1597464

<https://www.phoenixcontact.com/in/products/1597464>



RC-21P2400 - Crimp contact

1611637

<https://www.phoenixcontact.com/in/products/1611637>



Crimp contact, Pin, rolled, Taped product, number of pieces per reel: 10000, contact diameter: 1 mm, crimp range: 0.08 mm² ... 0.22 mm²

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

info@phoenixcontact.co.in