


Front panels, U profile, shieldable

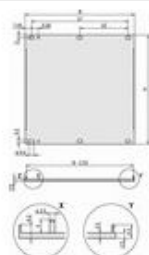

Product illustrations are exemplary illustrations and can deviate from supplied products.

Part no.: 30848-355

Features:

- High stability through U profile
- Front panel, U profile, Al, front anodised, rear conductive, 2 alignment pins pressed-in, stainless steel
- Differences in the finish between 2 ... 12 HP and 14 ... 84 HP

Add to basket



Standard pack quantity 5



Technical information:

Height	Height	Width	B	b1	b2	Alignment pin
6 U	261,8 mm	4 HP	20 (mm)			x

Downloads:

Download CAD data in DWG format ([Log in](#) Required)
Download CAD data in DXF format ([Log in](#) Required)

To gain access to the additional information you must [Log in](#).
If you do not yet have a user name, you may [Register here](#).

Accessories:

Part no.	Description	
21101-855	Textile EMC gasket 6 U, PU 10 pieces This accessory qualifies for our Front Panel Express service	Add to basket
21101-856	Textile EMC gasket 6 U, PU 100 pieces	Add to basket

Note:

- Standard pack quantity:
2 to 28 HP: 5 pieces,
42 to 84 HP: 1 piece,
supplied in standard pack quantities (SPQ) only
- Please order EMC profile seal and fixing materials separately