


Datasheet

RS Pro 1 kW Straight Immersion Tank Heater, Incoloy Nickel Iron Chromium Alloy Heating Element, 220 V ac

RS Stock No: **200-1235**

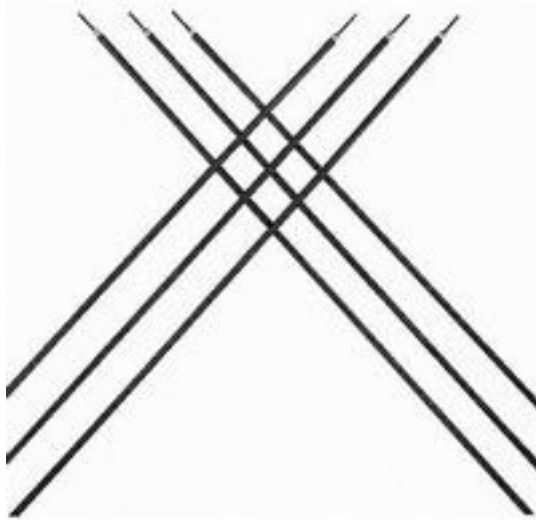

Product Details

RS Pro straight immersion tank heating element has an incoloy nickel iron chromium alloy construction that is suitable for direct immersion or as a source of conduction, convection or radiant heating element. This heating element is supplied in a straight length, in an annealed condition and can be formed into complex shapes using simple bending tools. This straight immersion heating element is voltage rated for 220 V ac and has a power rating of 1 kW. It supports straight immersion up to 1524 mm.

Features and Benefits

- 1524 mm immersed length
- Power rating of 1 kW
- 7.9 mm heating element diameter
- Efficient, robust and long-lasting
- Can be brazed to supports/flanges or mounted using compression fittings



ENGLISH

Specifications:

Heating Element Material	Incoloy Nickel Iron Chromium Alloy
Tank Heater Type	Straight Immersion
Thermostat Included	No
Heating Element Diameter	7.9 mm
Immersed Length	1524 mm
Power Rating	1 kW
Supply Voltage	220 V ac