

Features

- **High-Security Steel Shackle** – Equipped with a strong, durable steel shackle for enhanced cut resistance and secure locking.
- **Durable ABS Body** – Reinforced ABS housing is non-conductive, non-sparking, and resistant to chemicals and corrosion for long-lasting safety.
- **Key Retention Mechanism** – Jack locking system prevents key removal until the padlock is properly locked, ensuring compliance with safety procedures.
- **Secure Locking System** – Comes with a unique coded brass key and 6-pin cylinder, offering a high level of security and key differentiation.
- **User-Friendly Design** – Ribbed ABS body provides easy grip and handling during application and removal.
- **Clear Safety Labelling** – Supplied with a “Danger” safety label on the front and a personnel identification label on the back for clear, compliant usage.

RS PRO Premier Lockout Safety Padlock with 46 mm Steel Shackle - Key Different- Yellow

RS Stock No.: 0603262



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

- *ABS body features carved ribs for easy gripping and handling.*
- *Supplied with a unique coded brass key and 6-pin cylinder for increased security with different locking combinations.*
- *Jack locking key mechanism prevents key release until the shackle is closed and the padlock is locked.*
- *Reinforced ABS body is non-conductive, non-sparking, and resistant to chemicals and corrosion.*
- *Supplied with "Danger" safety label on front and personnel identification label on the back.*
- *Suitable for both indoor and outdoor lockout applications.*
- *Supplied with individually coded keys for maximum security.*
- *Each padlock comes in a box with 1 key.*
- *Equipped with a 46 mm hardened steel shackle with key different operation.*

General Specifications


Type	Premier Lockout Safety Padlock
Material	ABS Body with Steel Shackle
Colour	Yellow
Package	Individual box & Outer Box

Mechanical Specifications

Padlock Dimensions	46mm X 6mm X 45mm X 43mm X 20mm
Shackle Height	46mm
Shackle Dia	6mm
Body Height	45mm
Body Width	43mm
Body Depth	20mm
Weight	92 Grams

Operation Environment Specifications

Withstand temperature	-20°C to 110°C.
-----------------------	-----------------

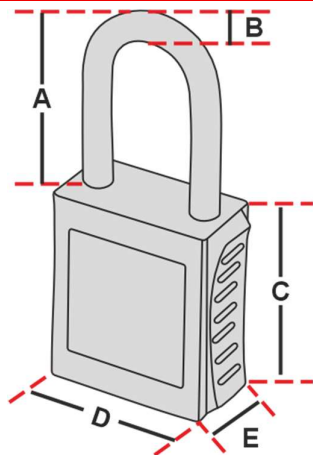

Dimension in mm

Model	ES-PLSP-KD
Shackle Height (A)	46
Shackle Dia (B)	6
Body Height (C)	45
Body Width (D)	43
Body Depth (E)	20