


Output circuits

Encoders



Push-pull
short circuit
protection

24K

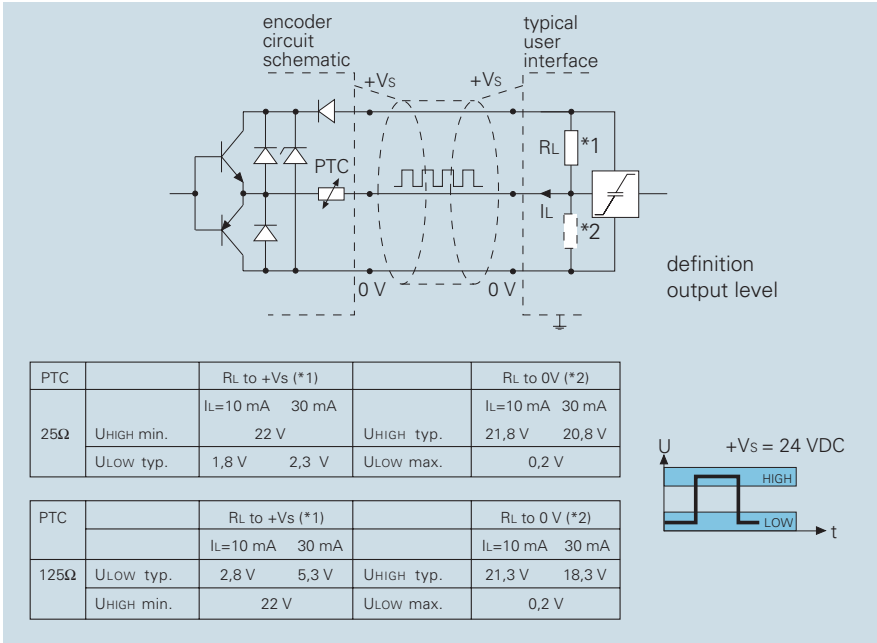

voltage supply	10 - 30 VDC reverse polarity protective
supply current	see product page
output current	max. 30 mA
PTC-resistance	25 Ω (BDK, BHK 125 Ω)