

# DYMO®



## LabelManager™ 160



### CREATE LABELS FAST WITH SMART KEYS

Just type your text, format it with one-touch smart keys and print!  
It's easy to create professional labels in and around the office.

#### Features

- Large LCD Display
- Computer-style keyboard
- One-touch Smart Keys for fast formatting
- 20+ ways to form text
- 200+ symbols and clip-art images
- Print up to 1/2 in (12mm) wide labels
- Powered by 6xAAA alkaline batteries (not included) or optional adapter



### Single Unit Includes:

- LabelManager 160
- D1 Starter Label Cassette, 12mm x 3m Black on White
- Quick Start Guide
- 2 + 1 - Year Limited Warranty\*



#### Quick Specs

|                             |                                 |
|-----------------------------|---------------------------------|
| Unit Dimensions (H x W x L) | 118 x 203 x 49 mm               |
| Weight (excluding battery)  | 350 g                           |
| Mac®/PC Compatible          | No                              |
| Accepts Label Sizes         | 6mm, 9mm and 12mm               |
| Tape Platform               | D1, Durables                    |
| Resolution                  | 180 dpi                         |
| Printing System             | Thermal Transfer                |
| Print Speed                 | 12 mm/sec                       |
| Barcodes                    | No                              |
| Cutter Type                 | Manual                          |
| Batteries                   | 6 AAA (not included)            |
| Adapter                     | Yes (optional, sold separately) |
| Networking                  | No                              |
| Country of Origin           | China                           |

| Item Number                       | Description             |      | Length (cm) | Width (cm) | Height (cm) | QTY | EAN           | Customer Price |
|-----------------------------------|-------------------------|------|-------------|------------|-------------|-----|---------------|----------------|
| 7545027                           | LabelManager 160 QWERTZ | Unit | 6.5         | 16.0       | 26.5        | 1   | 3501170946367 |                |
| <b>Accessories (www.dymo.com)</b> |                         |      |             |            |             |     |               |                |
| 7644219                           | Charging Adapter        | Unit | 11.5        | 6.0        | 9.0         | 1   | -             |                |

\* +1 year if registered on the DYMO® website

## D1 Standard Polyester Labels

For hundreds of tasks around the office or home office, such as filing, storage and asset tracking.  
Temperature rating: -18°C to 90°C




| D1 STANDARD LABELS (3 m)     | 6 mm  | 9 mm    | 12 mm   |
|------------------------------|---|---------|---------|
| ABC                          | Contact your RS Components team for availability. |         |         |
| ABC                          | Contact your RS Components team for availability. |         |         |
| D1 STANDARD LABELS (7 m)     | 6 mm  | 9 mm    | 12 mm   |
| ABC                          | 2086668   | 2030457 | 497432  |
| ABC                          | 2086630   | 2030441 | 497410  |
| ABC                          | 2086652   | 2030485 | 497476  |
| ABC                          | -   | 2170202 | 494641  |
| ABC                          | -   | 2170218 | 494657  |
| ABC                          | -   | 2030479 | 497460  |
| ABC                          | -   | -       | 2170189 |
| ABC                          | -   | 2170195 | 497448  |
| ABC                          | -   | -       | 494635  |
| ABC                          | -   | -       | 2172343 |
| ABC                          | -   | 2030463 | 497454  |
| ABC                          | -   | -       | 497426  |
| D1 STANDARD MULTIPACKS (7 m) | 6 mm  | 9 mm    | 12 mm   |
| ABC                          | -   | 1920480 | 1920481 |



## D1 Durable Vinyl Labels

Industrial strength adhesive helps to ensure labels stay stuck to a variety of surfaces.  
Temperature rating: -40°C to 80°C

| D1 DURABLE LABELS (3 m)   | 12 mm   |
|---------------------------|---------|
| ABC                       | 1245866 |
| ABC                       | 1245865 |
| ABC                       | 1245867 |
| D1 DURABLE LABELS (5.5 m) | 12 mm   |
| ABC                       | 1245864 |

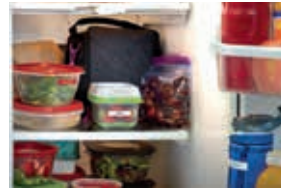

## D1 Permanent Polyester Labels

Professional, polished finish ideal for panels, blocks, faceplates, shelves, bins and more.  
Temperature rating: -40°C to 150°C\*

| D1 PERMANENT POLYESTER (5.5 m) | 12 mm   |
|--------------------------------|---------|
| ABC                            | 4493945 |

\*depends on surface



## D1 Flexible Nylon Labels

Specifically designed for curved surfaces and wire and cable marking.  
Temperature rating: -40°C to 60°C

| D1 FLEXIBLE NYLON (3.5 m) | 12 mm   |
|---------------------------|---------|
| ABC                       | 4493658 |



The DYMO® high quality labels are made in Belgium



© 2019 Newell Brands

This information is being provided for general information purposes and the compliance standards and certifications referenced herein are based on current standards which are subject to change.

