


HELAVIA flanged and bushed grommets
in polychloroprene rubber (Neoprene) black
(for technical properties see page D100)




HELAVIA
30 to + 90°C


type	article number	pack	type	article number	pack	type	article number	pack
15-001	0253 0002 010	100	15-305	0254 0033 010	100	15-653	0257 0043 010	100
15-003	0254 0023 010	100	15-393	0257 0013 010	100	15-654	0257 0044 010	100
15-004	0254 0045 010	100	15-395	0257 0014 010	100	15-664	0257 0050 010	100
15-038	0254 0025 010	100	15-398	0257 0015 010	100	15-665	0257 0051 010	100
15-058	0254 0026 010	100	15-399	0257 0016 010	100	15-678	0254 0088 010	100
15-060	0254 0046 010	100	15-537	0254 0087 010	100	15-716	0254 0005 010	100

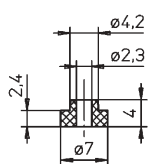


15-305
0254 0033 010

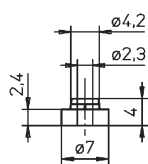


15-537
0254 0087 010

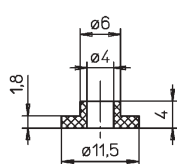


15-058
0254 0026 010

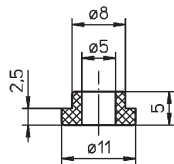


15-398
0257 0015 010

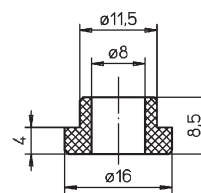


15-399
0257 0016 010

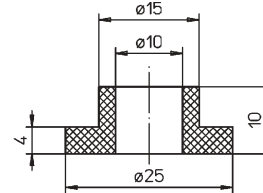


15-395
0257 0014 010

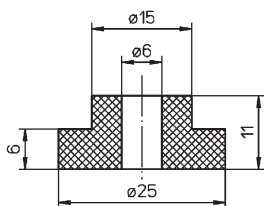


15-003
0254 0023 010

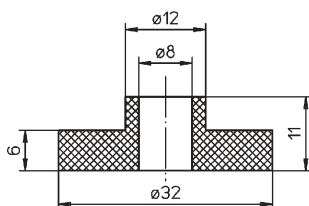


15-038
0254 0025 010

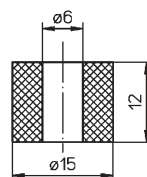


15-004
0254 0045 010

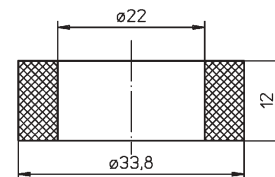


15-678
0254 0088 010

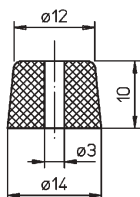


15-716
0254 0005 010

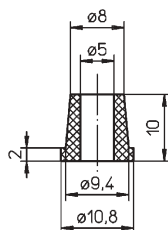


15-664
0257 0050 010
RS 136-7944

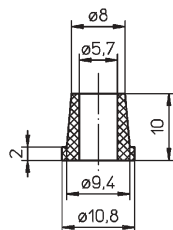


15-665
0257 0051 010
RS 136-7950

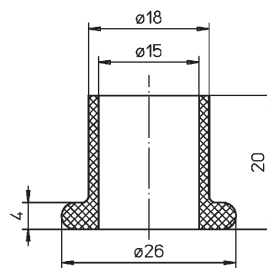


15-393
0257 0013 010

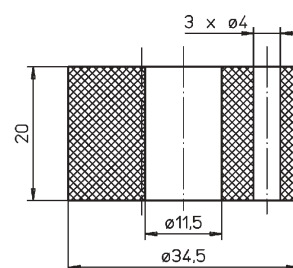


15-654
0257 0044 010

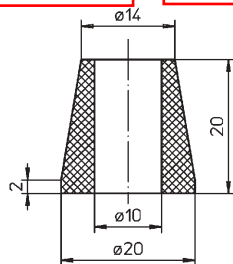

15-653
0257 0043 010

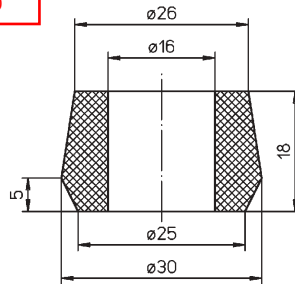

15-060
0254 0046 010

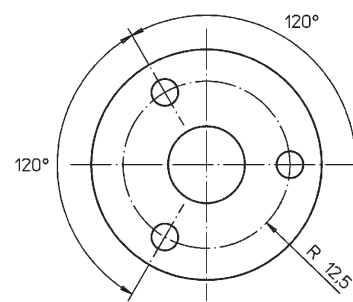

15-001
0253 0002 010