

Features

- Superimposable and stackable.
- These products are made from pre-consumer and post-consumer waste.
- Static load resistance: 50 kg (250 kg in stacked condition).
- Impact resistance: ~ 720 N (method EN 840-5 point 4.7.2).
- Working temperatures: from - 20 °C to +60 °C.
- External dimensions : 30x40x10 cm – capacity 9 liters

RS PRO Storage Bins

RS Stock No.: 0630946



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

These Euronorm plastic crates, in a large variety of sizes and options, are a standardized solution for storing, protecting and transporting goods suitable for warehouses, work stations, storerooms, assembly departments...

Upright lids are available separately. The peculiar feature of this range is the material, a recycled polypropylene coming from urban and industrial waste.

General Specifications

Type	Euronorm Crate
Portable	Yes
Bin Material	Recycled Plastic; PP (polypropylene)
Colour	Grey
For Use With	
Total (NL) No. of Louvres	
Capacity	9 litres
Pack Quantity	1
Finish	

External dimensions

Dimension	400 x 300 x 100mm
Overall Height	100mm
Overall Width	400mm
Overall Depth	300mm
Overall Base Length	

Internal dimensions

Dimension	365 x 265 x 95mm
Height	95mm
Width	365mm


Storage Bins



Depth	265mm
Base length	

Approvals

Compliance/Certifications	
Declarations	REACH, RoHS

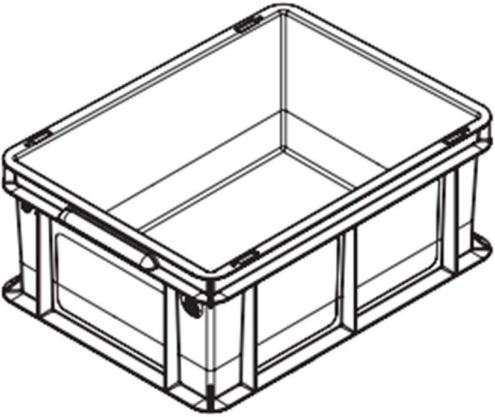

INCLUDES WITH PRODUCT: / STANDARD ACCESSORIES /
CONSTRUCTIONAL DIAGRAM