


Gear unit
EMGA-60-A-G5-60P
Part number: 8085345

FESTO

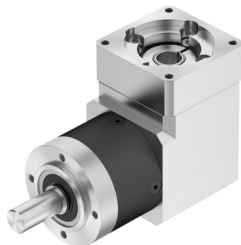

 [General operating condition](#)

Data sheet

Feature	Value
Gear unit flange size	60 mm
Motor flange size	60 mm
Torsional backlash	0.27 deg
Type of gear unit	Right-angle gear unit
Gear unit ratio	5:1
Max. drive speed	13000 rpm
Operating temperature of gear unit	-25 °C ... 90 °C
LABS (PWIS) conformity	VDMA24364-B2-L
Degree of protection	IP54
Continuous output torque	24 Nm
Mass moment of inertia of gear unit	0.257 kgcm ²
Max. output torque	38 Nm
Max. efficiency	95 %
Torsional rigidity	1.9 Nm/arcmin
Product weight	1700 g
Gear unit interface, output shaft	60G
Gear unit interface, drive shaft	60P
Note on materials	RoHS-compliant