



## AI 1 - 8 RD-B

Order No.: 3201385

The illustration shows version AI 1,5 - 8 in red

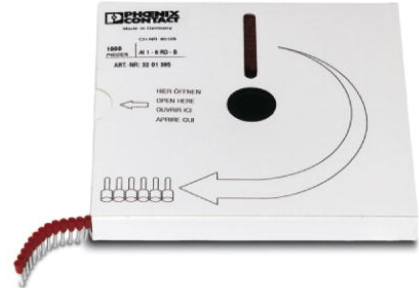

Ferrules, 1.0 mm<sup>2</sup>, taped, sleeve length: 8 mm, with plastic collar, galvanically tin-plated, color: red, color range according to DIN 46228-4, CSA-certified

| Commercial data          |  |
|--------------------------|--|
| GTIN (EAN)               | <br>4 017918 094881 |
| sales group              | B256   |
| Pack                     | 1000 pcs.  |
| Customs tariff           | 85369010   |
| Catalog page information | Page 335 (CL2-2011)  |

### Product notes

WEEE/RoHS-compliant since:  
03/03/2005



<http://www.download.phoenixcontact.com>  
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

| Technical data |       |
|----------------|-------|
| <b>General</b> |       |
| Length (b)     | 14 mm |
| Color          | red   |
| Material       | E-CU  |
| Sleeve length  | 8 mm  |

---

|  |         |
|--|---------|
| Inner dimension of the insulating collar (d) | 3 mm    |
| Ferrule diameter                             | 1.5 mm  |
| Insulating collar thickness                  | 0.3 mm  |
| Sleeve wall thickness                        | 0.15 mm |

**Certificates / Approvals**



Certification

CSA, CSAus-COMP

---

**Diagrams/Drawings**

Dimensioned drawing

