


13A Socket with Two 3.4A USB Charging Ports

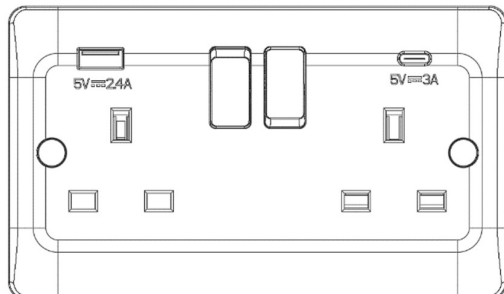

Description

13A Socket with high current USB charging ports, for simultaneous charging of smart phones, tablets and other portable devices.

This uniquely shaped range is easy to install, with clear bold terminal markings and is supplied in individual protective polybags suitable for display.

Features

- Contemporary designed profile
- Concave Rockers
- 2g 13A DP Switch Socket with two high powered USB charging ports
- USB ports deliver up to 3.4A (2.4A +1A simultaneously)
- Supplied with 10mm spacer for fitting into 25mm boxes
- 2-year guarantee

Technical Specification & Features

Supply voltage	240Vac
Socket rating	13A
Switch	double pole
USB ports output	"Phone" 5V 1,000mA "Tablet" 5V 2,400mA
Standby current	1.2mA
Terminal capacity	4 x 2.5mm ²
Front plate material	Urea formaldehyde (Curve) Steel (Evo)

Urea flammability classification UL94 grade V-0

Switches control 13A sockets, not USB charging ports

No user serviceable parts

Range

2 Gang Switched and 2 USB charging ports VP1289

Back Boxes

Minimum recommended depth

	Flush	Dry lining	Surface
	35mm	35mm	46mm
2g	DB165	DB2541	VP1229

The Pro USB socket can fit in 25mm back box using the spacer provided

Terminal Capacity

	2.5mm ²	4mm ²	6mm ²	10mm ²
L & N	4	3	2	1

Standards

- BS 1363-2
- BS 5733
- EN 60950-1