





RS Best.-Nr. 517-4443  
 RS Best.-Nr. 517-3276  
 RS Best.-Nr. 517-3333  
 RS Best.-Nr. 517-3298  
 RS Best.-Nr. 517-3355  
 RS Best.-Nr. 517-3412  
 RS Best.-Nr. 517-3260  
 RS Best.-Nr. 517-4437  
 RS Best.-Nr. 517-3305  
 RS Best.-Nr. 517-3361  
 RS Best.-Nr. 517-3383  
 RS Best.-Nr. 517-3327  
 RS Best.-Nr. 517-3311  
 RS Best.-Nr. 517-3377  
 RS Best.-Nr. 517-3399


## Einfacher Hochtemperaturkasten (ohne Dichtung, keine Beschichtung)

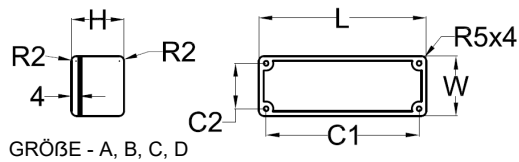


GRÖÖBE - A, B, C, D

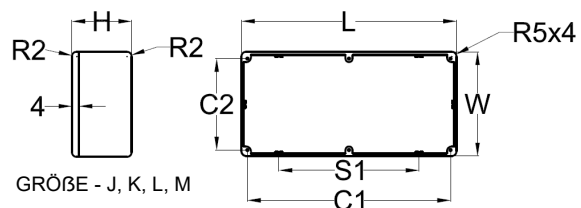


GRÖÖBE - J, K, L, M

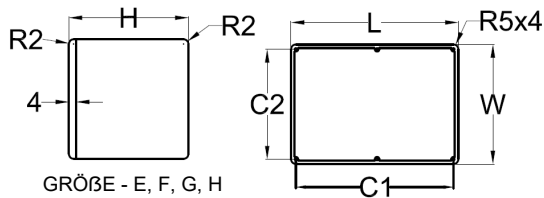

GRÖÖBE - E, F, G, H

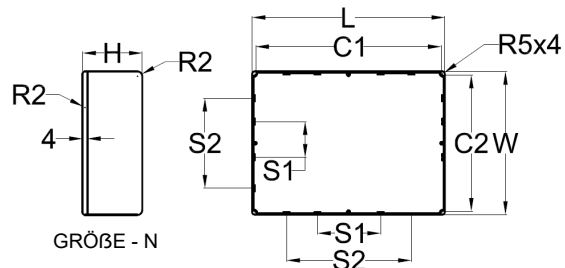

GRÖÖBE - N

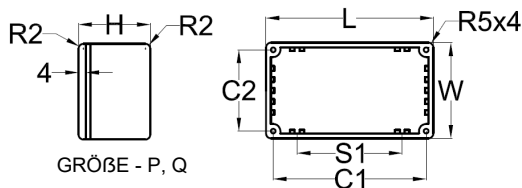

GRÖÖBE - P, Q

Best.-Nr.	Größe NR.	L	W	H	C1	C2	S1	S2	Wandstärke
5174443	A	89,1	35,0	30,3	79,3	25,3			1,5 mm
5173276	B	114,5	63,6	30,3	104,5	54,2			1,5 mm
5173333	C	114,7	89,7	55,1	104,4	79,6			1,5 mm
5173298	D	114,4	63,7	55,1	104,6	54,2			1,5 mm
5173355	E	171,9	120,9	55,0	160,4	109,3			2 mm
5173412	F	171,9	120,9	106,0	160,4	109,3			2 mm
5173260	G	222,1	145,9	55,9	211,7	135,4			2 mm
5174437	H	222,2	146,0	106,5	211,7	135,4			2 mm
5173305	J	275,0	175,0	65,5	264,1	164,0	132,2		2 mm
5173361	K	139,1	101,5	76,7	128,7	90,7	64,8		2 mm
5173383	L	165,8	127,3	76,3	154,0	116,1	77,1		2 mm
5173327	M	119,9	100,0	35,7	108,5	88,4	50,1		2 mm
5173311	N	250,2	250,2	100,5	238,0	238,0	79,9	160,0	2,5 mm
5173377	P	79,9	54,9	25,5	70,5	45,4	40,0		1,5 mm
5173399	Q	60,0	54,9	30,0	50,6	45,4	30,0		1,5 mm

1. Material von Sockel und Deckel: Aluminiumlegierung ADC12
2. Material der Schrauben: Edelstahl M3,5 x 9 mm Supadrive-Senkopf
3. Oberfläche: Natürlich, einfach

4. Verjüngung  $1,5^\circ$  pro Seite vom Deckel zum Sockel