


EUREKA Series

CONNECTORS


Rated operating voltage > 50 V

Reference standards: EN 60309-1 and EN 60309-2

STRAIGHT

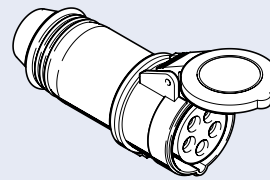

IP44

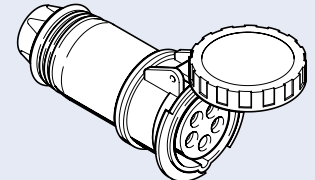

IP66/67

Poles	Hz	Volt	Colour	Inlet Pack Quantity: h	IP44		IP66/67	
					16 A cable sleeve 10/100	32 A cable sleeve 10/50	16 A cable gland 10/100 ¹	32 A cable gland 10/40
2P+E	50/60	100-130		4	311.1640 311.1640G *	311.3240 311.3240G *	316.1640	316.3240
	50/60	200-250		6	311.1643 311.1643G *	311.3243 311.3243G *	316.1643	316.3243
	50/60	380-415		9	311.1648	311.3248	316.1648	316.3248
	60	277		5	311.16437	311.32437	316.16437	316.32437
	50/60	480-500		7	311.16436	311.32436	316.16436	316.32436
	50/60	is. transf.		12	311.16433	311.32433	316.16433	316.32433
	>300-500	>50		2	311.16432	311.32432	316.16432	316.32432
	d.c.	>50-250		3	311.16434	311.32434	316.16434	316.32434
	d.c.	>250		8	311.16438	311.32438	316.16438	316.32438
3P+E	50/60	100-130		4	311.1641	311.3241	316.1641	316.3241
	50/60	200-250		9	311.1644	311.3244	316.1644	316.3244
	50/60	380-415		6	311.1646 311.1646G *	311.3246 311.3246G *	316.1646	316.3246
	60	440-460		11	311.16465	311.32465	316.16465	316.32465
	50/60	480-500		7	311.16466	311.32466	316.16466	316.32466
	50/60	600-690		5	311.16467	311.32467	316.16467	316.32467
	50/60	is. transf.		12	311.16463	311.32463	316.16463	316.32463
	50 60	380 440		3	311.16464	311.32464	316.16464	316.32464
	100-300	>50		10	311.16461	311.32461	316.16461	316.32461
	>300-500	>50		2	311.16462	311.32462	316.16462	316.32462
3P+N+E	50/60	100-130		4	311.1642	311.3242	316.1642	316.3242
	50/60	208-250		9	311.1645	311.3245	316.1645	316.3245
	50/60	346-415		6	311.1647 311.1647G *	311.3247 311.3247G *	316.1647	316.3247
	50/60	480-500		7	311.16476	311.32476	316.16476	316.32476
	50/60	600-690		5	311.16477	311.32477	316.16477	316.32477
	60	440-460		11	311.16475	311.32475	316.16475	316.32475
	50 60	380 440		3	311.16474	311.32474	316.16474	316.32474
	>300-500	>50		2	311.16472	311.32472	316.16472	316.32472

*Glanded version

¹3P+N+E=Pack Qty. 10/40