

FLIR FX™

WIRELESS HD VIDEO MONITORING

The **FLIR FX** is a versatile wireless HD camera that allows you to keep an eye on the things you care about – anytime, any place. Monitor your home or business, inside or out with the adaptable camera and housings. Take the camera on the go, and never miss the action while driving or on an outdoor adventure.



INDOOR CAMERA

Never miss a thing – records 1080p to an on-board microSD card.

- **RapidRecap™:** See the day in a minute. Review hours of footage simultaneously.
- **SmartZone™:** Recordings and alerts only happen when motion is detected in areas you select.
- **Battery:** Portable, cordless operation with a four-hour internal battery.
- **Night Vision:** See up to 33ft (10m) in the dark.



OUTDOOR CAMERA

Bring outdoor security to the next level with the weatherproof housing.

- **RapidRecap™:** See the day in a minute. Review hours of footage simultaneously.
- **Weatherproof:** IP67 housing protects camera from dust, water, and low temperatures (-4°F/-20°C).
- **Audio:** Supports 2-way audio communication with built-in speakers and microphone.
- **Night Vision:** Infrared LEDs for increased night vision up to 65ft (20m).



SPORT HOUSING

Capture the action in stunning HD with the optional waterproof Sport Housing.

- **Waterproof:** Submersible to 64ft (20m) with waterproof IP68 rating.
- **Onboard Recording:** Records 1080p to an on-board microSD card.
- **Battery:** Two-hour internal battery.
- **Mounting:** Compatible with any ¼"-20 thread mount accessory.




DASH MOUNT


The optional Dash Mount lets you see it all while on the road with in-vehicle dashboard recording.

- **Internal Accelerometer:** Automatically records when your vehicle is in motion.
- **Loop Recording:** Continuous 30-minute, 1080p loop recording.
- **Emergency Recording:** Resulting from any strong braking or impact.
- **Mounting:** Includes suction cup mount with 360° pivot.


FX Camera - Common features	
Image Sensor	4MP, 1/3" CMOS
Resolution	Up to 1920 x 1080 (1080p)
Horizontal Field of View	Up to 160°
Frame Rate	Up to 30 FPS
Compression	H.264
Lens	2.45mm / F2.5
WiFi	2.4GHz 802.11 b/g/n
Apps	iOS, Android
LED Indicators	Cloud mode, direct mode, recording, charging
MicroSD	8GB-64GB microSDHC or microSDXC supported, class 10 or higher
Battery - Camera Only	1130mAh
Battery Life - Camera Only	Up to 2 hours
Dimensions - Camera Only	2.0" x 1.2" x 2.3" (51mm / 31mm / 59mm)
Weight - Camera Only	0.2 lb / 0.08 kg
Operating Temperature	32°F ~ 104°F / 0°C ~ 40°C
Operating Humidity	10 ~ 90% NC
USB	microUSB for power / USB storage mode
Power Adapter	5V / 2.0A

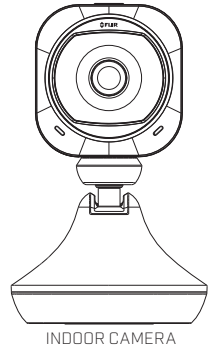


INDOOR CAMERA

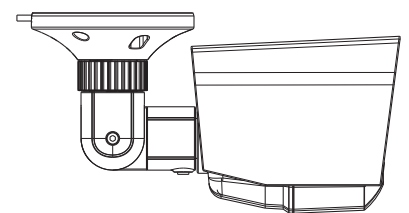

OUTDOOR CAMERA

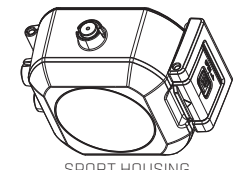

SPORT HOUSING

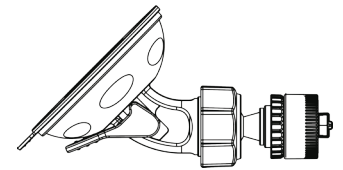

DASH MOUNT

FX Stands - Specialized Features				
Style	Indoor	Outdoor	Sport	Dash
Model	FXV101-H	FXV101-W/FXAW01	FXAS01	FXAD01
Max. recording resolution (to microSD)	1080p to microSD/ WVGA to Cloud	1080p to microSD/ WVGA to Cloud	1080p	1080p
Still Image Capture	4MP	4MP	4MP	N
RapidRecap™	Y	Y	N	N
SmartZone™	Y	Y	N	N
Night Vision (LEDs, Range)	6 IR LEDs / 33ft (10m)	4 IR LEDs / 65ft (20m)	N	N
Buttons	Y	N - can access functions from App	Y	Y
Microphone	Y	N	N	N
Speakers	Y	N	N	N
Accelerometer	N	N	N	Y - 0.5 G
Battery Life	4 Hours	N/A	2 Hours	2 Hours
Environmental rating	Indoor Only	IP67 weatherproof	IP68 Submersion to 65ft / 20m	Inside vehicle only
Temperature Sensor	Y	Y	N	N
Humidity Sensor	Y	N	N	N
Operating Temperature	32°F ~ 104°F / 0°C ~ 40°C	-4°F ~ 104°F / -20°C ~ 40°C	32°F ~ 104°F / 0°C ~ 40°C	32°F ~ 104°F / 0°C ~ 40°C
Product Weight	0.45 lb / 0.2 kg	0.9lbs / 0.4kg / 0.7lbs / 0.3kg	0.1lbs / 0.04kg	0.01lb / 0.005kg
Product Dimensions (L x W x H)	2.7" x 2.3" x 4.7" (70mm x 60mm x 121mm)	6.8" x 3.5" x 3.7" (175mm x 89mm x 94mm)	3.3" x 3.1" x 1.3" (84mm x 80mm x 34mm)	2.1" x 2.1" x 5.0" (54mm x 54mm x 127mm)

CANADA
 FLIR Systems - Canada
 250 Royal Crest Court
 Markham, Ontario,
 Canada L3R 3S1

BALTIMORE
 901 Elkridge Landing RD
 Linthicum, MD 21090
 USA
 PH: +1 888.425.6739

www.flir.com
 NASDAQ: FLIR

Equipment described herein may require US Government authorization for export purposes. Diversion contrary to US law is prohibited. Imagery for illustration purposes only. Specifications are subject to change without notice. ©2015 FLIR Systems, Inc. All rights reserved.

Model	FXV101-H:	FXV101-W	FXAW01	FXAS01	FXAD01
Includes	1 x FX HD Camera, 1 x 10' USB Cable, 1 x Indoor Stand, 1 x MicroSD Card, 1 x Wall Mounting Hardware, 1 x International USB power adapter	1 x FX HD Camera, 1 x Outdoor housing, 1 x Screws and anchors kit, 1 x Mounting stencil, 1 x 13 ft (4m) power adapter cable	1 x Outdoor housing, 1 x Screws and anchors kit, 1 x Mounting stencil, 1 x 13 ft (4m) power adapter cable	1 x Sport case (compatible with 1/4"-20 camera accessories), 1 x Ball & socket stand, 3 x 3M surface mounts	1 x Suction cup mount, 1 x Car charger, 1 x USB cable
UPC	8-41430-00983-2	8-41430-00984-9	8-41430-00982-5	8-41430-00980-1	8-41430-00979-5
Package Weight	1.61 lb/0.73 kg	2.07 lb/0.94 kg	1.17 lb/0.53 kg	1.76 lb/0.80 kg	0.62 lb/0.28 kg
Package Dimensions (L x W x H)	7.48" x 2.76" x 8.27" (190mm x 70mm x 210mm)	7.48" x 3.94" x 8.27" (190mm x 100mm x 210mm)	7.48" x 3.94" x 8.27" (190mm x 100mm x 210mm)	6.18" x 5.67" x 2.28" (190mm x 100mm x 210mm)	7.48" x 2.76" x 8.27" (157mm x 70mm x 210mm)