


Item	Unit	Specification	Condition
Resonant frequency	KHz	3.7 ± 0.5	
Operating Volt. range	VDC	3 ~ 20	
Current consumption	mA	MAX 10	at 12VDC
Sound pressure level	dB	MIN 95	at 30cm/12VDC
Rated Voltage	VDC	12	
Tone		Continuous	at 12VDC
Operating temp.	°C	-30 ~ +85	
Storage temp.	°C	-40 ~ +95	
Dimension	mm	φ31.5 x H14.4	See appearance drawing
Weight (MAX)	gram	7.0	
Material		ABS UL-94 1/16" HB HIGH HEAT (BLACK)	
Terminal		Pin type (Plating Sn)	See appearance drawing
Environmental Protection Regulation		RoHS	
Storage life	month	6	6 months preservation at room temp. (25±3°C), Humidity40% 下25±3°C,40%.

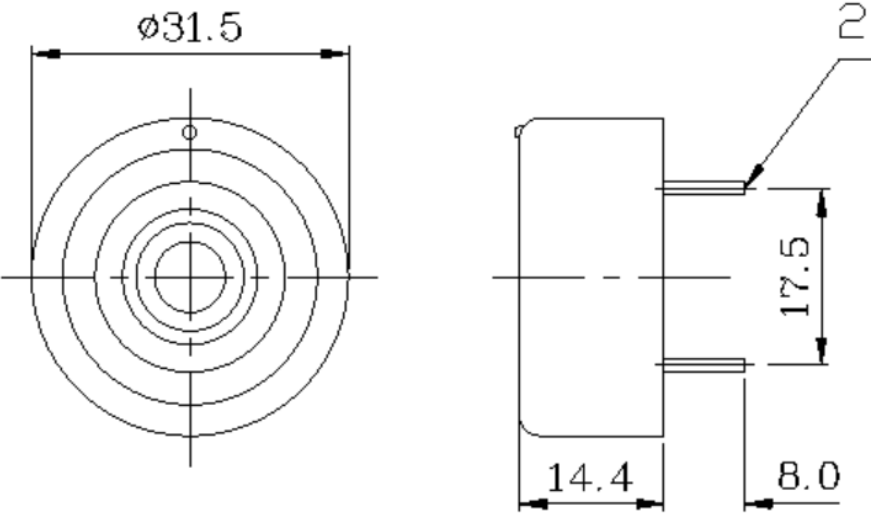

Tol : ± 0.5

Unit : mm