


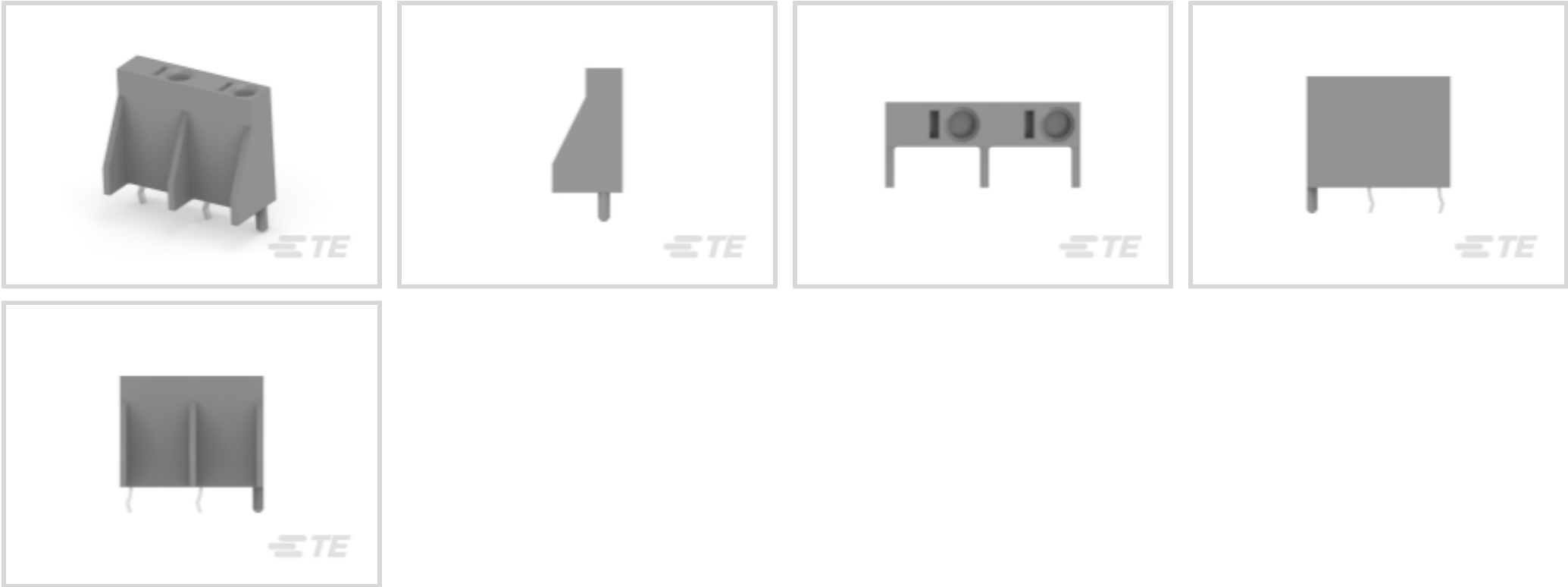

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 2213629-3
ASY,IN-LINE VERT SCRLESS,SPECIAL
PACK




TE Part # 1-2008552-2
CONNECTOR, INLINE VERT
SCREWLESS



TE Part # 1811957-1
ASY,SCRLESS WIRE CONN,VERT,2P
SCREWLESS

Customers Also Bought

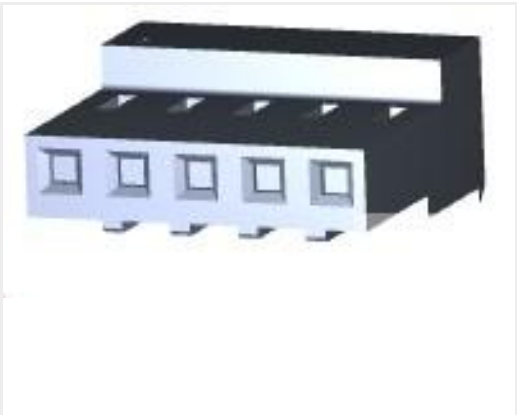

TE Part #3-640432-5
05P MTA156 CONN ASSY 20AWG YEL



TE Part #60755-2
187 FASTON FLAG REC 20-16 AWG
TPBR



TE Part #2336396-2
ASSEMBLY, LIGHT CONTROLLER
BASE, W/VENT




TE Part #2315539-1
COVER, LIGHT CONTROLLER, 81MM
DIA., 62MM



TE Part #2213629-3
ASY,IN-LINE VERT SCRLESS,SPECIAL
PACK




TE Part #3-640432-4
04P MTA156 CONN ASSY 20AWG YEL

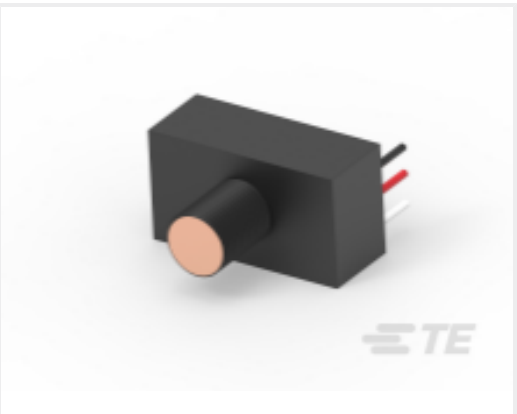

TE Part #131520-000
ALR-AA-1068



TE Part #3-640432-3
03P MTA156 CONN ASSY 20AWG YEL

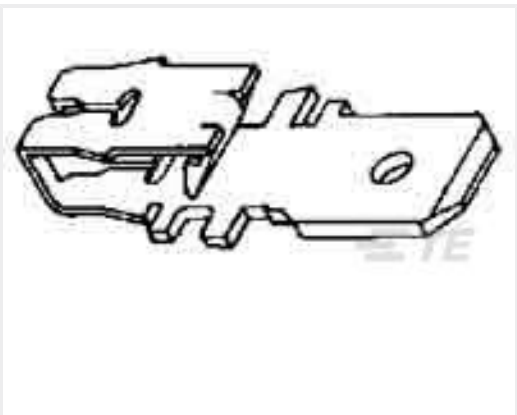

TE Part #63668-1
MAG-MATE 187 F-TAB TPBR



TE Part #63666-1
MAG-MATE 187 FAST TAB 020TPBR

Documents

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1-2213629-2_C.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1-2213629-2_C.3d_igs.zip

English



Customer View Model

[ENG_CVM_CVM_1-2213629-2_C.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[BUCHANAN WireMate Connectors Brochure](#)

[BUCHANAN WireMate Connectors Brochure](#)

English

[Vertical and In-Line Screwless Wire Connectors](#)

English

Product Specifications

[Application Specification](#)

English

Agency Approvals

[UL Report](#)

English