

Hand bolt

Thumb screws



<Features>

The screw part is made of steel and has been plated with trivalent chromate (light bluish color) to improve corrosion resistance. The resin part is made of ABS resin. A screw that can be tightened with a screwdriver or by hand.


<Application>

It is used for tightening parts where you want to repeatedly remove screws by hand without using tools.

<Material>

Screw part : steel, resin part: ABS
Surface treatment thread : trivalent chromate plating

No	Model number
1	Thumb screws NO.1 3X6
2	Thumb screws NO.1 3X8
3	Thumb screws NO.1 3X10
4	Thumb screws NO.1 3X12
5	Thumb screws NO.2 4X8
6	Thumb screws NO.2 4X10
7	Thumb screws NO.2 4X12
8	Thumb screws NO.2 4X15

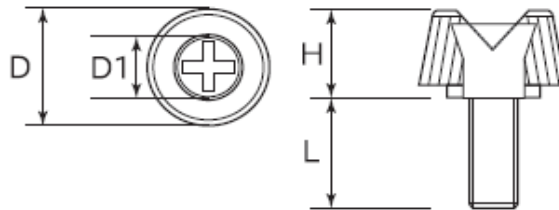

Size	D	D1	H
M3	11	4.2	5.1
M4	15	6	6



ボルト 手回しボルト

ボルト

小ねじ

ナット

ねじ付属

タッピング

ドリルねじ

木ねじ

アンカー・プラグ

フック

釘・鉚

建築用金具・ねじ・釘

住宅基礎

波板関連

外壁・天井関連

手すり・パイプ

配管部材

ロープ・ワイヤー

チェーン

DIYシリーズ

隅金

ステー・補助金具

棚受け金具

キャスター

戸車

針金

ばね

鍵・錠

ゴム

安全用品

金属素材


カー用品

SCAN・その他

現場改善

健康

プラポイント

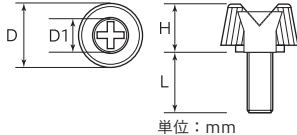

サイズ	D	D1	H
M3	11	4.2	5.1
M4	15	6.0	6.0

※L=ねじ長さ
※ドライバー2番使用


特長 ねじ部の材質は鋼で耐食性向上のため、三価クロメートめっき(薄青っぽい色合い)がしてあります。樹脂部はABS樹脂。ドライバーでも手回しでも締結可能なねじです。

用途 工具を使わず手で繰り返しねじを脱着したい個所の締付けに使用します。

材質 ねじ部：鋼、樹脂部：ABS (表面処理) ねじ部：三価クロメートめっき

JAN	サイズ	入数	LOT
4979874871923	NO.1 3X6	4	5
4979874871930	NO.1 3X8	4	5
4979874871947	NO.1 3X10	4	5
4979874871954	NO.1 3X12	4	5
4979874871961	NO.2 4X8	4	5
4979874871978	NO.2 4X10	4	5
4979874871985	NO.2 4X12	4	5
4979874871992	NO.2 4X15	4	5

コインスクリュー

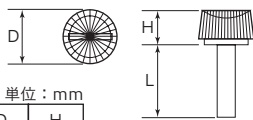

サイズ	D	H
M3	12.5	7
M4		

※L=ねじ長さ
※コイン用溝深さ 2mm
※コイン用溝幅 1.74mm


特長 ねじ部の材質は鋼で耐食性向上のため、三価クロメートめっき(薄青っぽい色合い)がしてあります。樹脂部はナイロン6。コイン形状、手回しで締結可能なねじです。コイン形状で締められるので手回しでは締結が不安な方におすすめです。

用途 工具を使わず手で繰り返しねじを脱着したい個所の締付けに使用します。

材質 ねじ部：鋼、樹脂部：ナイロン6 (表面処理) ねじ部：三価クロメートめっき

JAN	サイズ	入数	LOT
4979874872050	NO.1 3X6	4	5
4979874872067	NO.1 3X8	4	5
4979874872074	NO.1 3X10	4	5
4979874872081	NO.1 3X12	4	5
4979874872098	NO.1 4X8	4	5
4979874872104	NO.1 4X10	4	5
4979874872111	NO.1 4X12	4	5
4979874872128	NO.1 4X15	4	5

ナイロン蝶ボルト

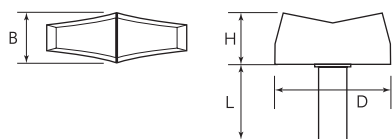

サイズ	B	D	H
M3	8.5	18	10.5
M4			
M5	11.5	28	15

※L=ねじ長さ

特長 ねじ部の材質は鋼で耐食性向上のため、三価クロメートめっき(薄青っぽい色合い)がしてあります。樹脂部はナイロン6。手回しで締めつけが可能なねじです。つまみやすさを追求した形です。

用途 工具を使わず手で繰り返しねじを脱着したい個所の締付けに使用します。

材質 ねじ部：鋼、樹脂部：ナイロン6 (表面処理) ねじ部：三価クロメートめっき

JAN	品名	サイズ	入数	LOT
4979874872135	ナイロン蝶ボルト	NO.1 3X10	2	5
4979874872142	ナイロン蝶ボルト	NO.1 3X15	2	5
4979874872159	ナイロン蝶ボルト	NO.1 4X10	2	5
4979874872166	ナイロン蝶ボルト	NO.1 4X15	2	5
4979874872173	ナイロン蝶ボルト	NO.2 5X10	2	5
4979874872180	ナイロン蝶ボルト	NO.2 5X15	2	5

メーカー型番 (JAN) - RS Web表示型番対比表

No	製品名	JAN	サイズ	RS Web表示型番
1	プラポイント	4979874871923	NO.1 3X6	Thumb screws NO.1 3X6
2	プラポイント	4979874871930	NO.1 3X8	Thumb screws NO.1 3X8
3	プラポイント	4979874871947	NO.1 3X10	Thumb screws NO.1 3X10
4	プラポイント	4979874871954	NO.1 3X12	Thumb screws NO.1 3X12
5	プラポイント	4979874871961	NO.2 4X8	Thumb screws NO.2 4X8
6	プラポイント	4979874871978	NO.2 4X10	Thumb screws NO.2 4X10
7	プラポイント	4979874871985	NO.2 4X12	Thumb screws NO.2 4X12
8	プラポイント	4979874871992	NO.2 4X15	Thumb screws NO.2 4X15