



## 16. N-Abschirmkappe/N-Hoods

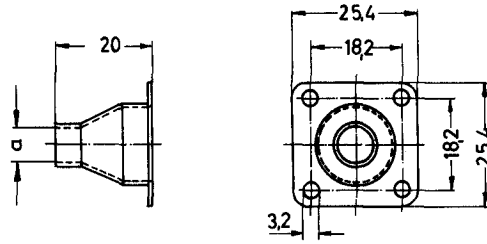

Bestell-Nr. Order Nr.	MIL-Std. MIL-Std.	Kabel-Type Cable type	Anmerkungen Remarks
C05000A0654	UG 177/U	Ø 3,9	J 2
C05000A0655	UG 106/U	Ø 8,7	J 2
C05000A0656	UG 372/U	Ø 9,1	J 2

## 17. Knickschutzfüllen/Cable Reliefs

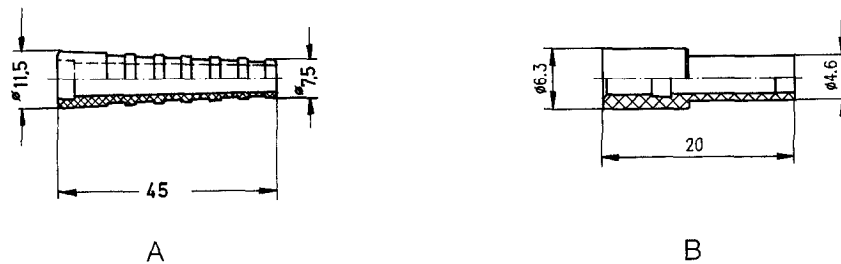

Bestell-Nr. Order Nr.	Kabel-Type Cable type	Anmerkungen Remarks
B00081A1272	RG 58 C/U	A schwarz black
B00081B1272	RG 58 C/U	A rot red
B00081C1272	RG 58 C/U	A blau blue
B00081D1272	RG 58 C/U	A gelb yellow
B00081E1272	RG 58 C/U	A grün green
B00081F1272	RG 58 C/U	A orange orange
B00081G1272	RG 58 C/U	A grau grey
B00081H1272	RG 58 C/U	A braun brown
B00081J1272	RG 58 C/U	A violett violet
B00081K1272	RG 58 C/U	A weiß white
B00081A1289	RG 62 A/U; RG 59 B/U; 0,6/3,7	A schwarz black
B00081B1289	RG 62 A/U; RG 59 B/U; 0,6/3,7	A rot red
B00081C1289	RG 62 A/U; RG 59 B/U; 0,6/3,7	A blau blue
B00081D1289	RG 62 A/U; RG 59 B/U; 0,6/3,7	A gelb yellow
B00081E1289	RG 62 A/U; RG 59 B/U; 0,6/3,7	A grün green
B00081F1289	RG 62 A/U; RG 59 B/U; 0,6/3,7	A orange orange
B00081G1289	RG 62 A/U; RG 59 B/U; 0,6/3,7	A grau grey
B00081H1289	RG 62 A/U; RG 59 B/U; 0,6/3,7	A braun brown
B00081J1289	RG 62 A/U; RG 59 B/U; 0,6/3,7	A violett violet
B00081K1289	RG 62 A/U; RG 59 B/U; 0,6/3,7	A weiß white
B00080A0002	RG 174/U; RG 188/U; RG 316/U	B schwarz black
B00080B0002	RG 174/U; RG 188/U; RG 316/U	B rot red
B00080C0002	RG 174/U; RG 188/U; RG 316/U	B blau blue
B00080D0002	RG 174/U; RG 188/U; RG 316/U	B grün green