

Dual 4K Monitor Mini Thunderbolt 3 Dock with HDMI - Mac & Windows Docking Station -
Discontinued, Limited Stock, & Replaced by TB3DKM2HDL (TB3DKM2HD)

Product ID: TB3DKM2HD



This Thunderbolt 3 docking station packs big performance into a cost-effective, compact mini dock, delivering essential connections for productivity. The bus-powered Thunderbolt 3 dock lets you connect to dual 4K HDMI displays, Gigabit Ethernet and two USB (Type-A) ports and for a flexible setup, the attached USB-C cable has an extended length of (7.9 in./ 20 cm).

Great for editing 4K video or other Ultra HD tasks, this portable Thunderbolt 3 to HDMI dock supports 40Gbps of throughput and 4K resolution at 60Hz on dual HDMI monitors, through a single Thunderbolt 3 port. Run resource-demanding applications on two independent displays without draining system resources.

Connect your laptop to:

- 2x 4K HDMI displays (up to 4096 x 2160p @ 60Hz)

Simply connect the TB3 dock to your laptop with included TB3 cable and start working immediately. No time-consuming driver installations are required.

To enhance your productivity, the Gigabit Ethernet port (with PXE Boot and Wake-on-LAN support) ensures reliable wired network access. A USB 3.0 Type-A port, with ample space around it, lets you connect a USB device, such as a flash drive, for easy file access. Connect another USB device using the USB 2.0 Type-A port.

The TB3DKM2HD is Thunderbolt Certified, and backed by a StarTech.com 3-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility

Applications

- Review/edit images or media files on two 4K HDMI displays
- Transfer a 4K movie in under 30 seconds
- Ideal for shared or temporary work stations, such as hot desks (hoteling)


Features

- REPLACED BY TB3DKM2HDL: New version offers the same functionality plus, extra-long 11" (28cm) attached cable provides extended reach to reduce port/connector strain on MacBook's and laptops on riser stands
- Dual UHD 4K HDMI monitors at 60Hz to your laptop with this portable Thunderbolt 3 docking station; Windows and macOS compatible
- Extended dual displays on MacBook Pro/Air with Intel processor & single display with Apple M1 Chip
- Wired network and device connectivity with 2x USB-A ports (1x USB 3.0 and 1x USB 2.0) and Gigabit Ethernet
- Bus-powered (no external power required) via extended length 7.8 in. (20 cm) cable; compact design in durable aluminum

Hardware

Warranty	3 Years
4K Support	Yes
Fast-Charge Port(s)	No
Displays Supported	2
Bus Type	Thunderbolt 3
Industry Standards	Thunderbolt 3 IEEE 802.3, IEEE 802.3u, IEEE 802.3ab USB 3.0 - Backward compatible with USB 2.0 and 1.1 USB 2.0 - Backward compatible with 1.1
Chipset ID	Intel - Alpine Ridge JHL6540 Intel - WGI210AT Texas Instruments - TPS65983 ASMedia - ASM1042A Parade - PS176

Performance

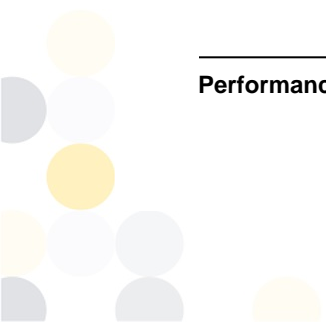

Maximum Data Transfer Rate	40 Gbps (Thunderbolt 3) 5 Gbps (USB 3.0) 2 Gbps (Ethernet; Full-Duplex)
Maximum Digital Resolutions	Dual 4K displays - HDMI 4096 x 2160p @ 60Hz / 3840 x 2160p @ 60Hz
Type and Rate	Thunderbolt 3 - 40 Gbit/s
UASP Support	Yes
Compatible Networks	10/100/1000 Mbps
Auto MDIX	Yes
PXE	Yes
Full Duplex Support	Yes

Connector(s)

Connector Type(s)	Thunderbolt 3 USB-C (24-pin) (40Gbps) HDMI (19 pin) USB Type-A (9 pin) USB 3.0 (5 Gbps) USB Type-A (4 pin) USB 2.0 RJ-45
-------------------	--

Software

OS Compatibility	Windows 7, 8, 8.1, 10 >macOS 10.12 - 10.15, 11.0
------------------	---

Special Notes / Requirements

System and Cable Requirements	Thunderbolt 3 equipped computer with a Thunderbolt 3 port.
Note	A 4K-capable display is required to achieve 4K x 2K resolution (4K is also known as 4K x 2K). MacBook Air and MacBook Pro systems using the new Apple M1 chip support only a single external display over the Thunderbolt 3 ports, even when connected to a Thunderbolt 3 docking station with more than one video output. This single monitor limitation does not affect Intel-based Macs with Thunderbolt 3.

Power

Power Source	USB-Powered
--------------	-------------

Environmental

Operating Temperature	5C to 35C (41F to 95F)
Storage Temperature	-40C to 70C (-40F to 158F)
Humidity	5~95% RH (Non-condensing)

Physical Characteristics

Color	Black & Gray
Material	Aluminum
Cable Length	7.9 in [20 cm]
Product Length	4.9 in [12.4 cm]
Product Width	2.4 in [61.0 mm]
Product Height	0.7 in [18.8 mm]
Weight of Product	5.1 oz [145.8 g]

Packaging Information

Package Length	8.2 in [20.8 cm]
Package Width	5.7 in [14.5 cm]
Package Height	1.4 in [36.0 mm]
Shipping (Package) Weight	9.2 oz [260.0 g]

What's in the Box

Included in Package	Docking Station
	User Manual

****Product appearance and specifications are subject to change without notice.***

