




PRINT ANY LABEL OR SIGN

i3300

INDUSTRIAL LABEL PRINTER

The **i3300 Industrial Label Printer** is a completely hassle free, easy to use PC-based printer.

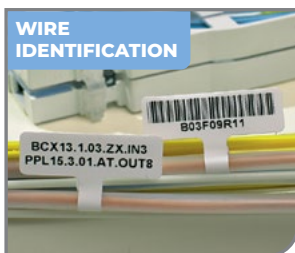

Print a full range of safety and facility labels, signs and die cut labels for wire identification, product identification and laboratory identification.

- ▶ Seamless monocolour labels
- ▶ 50+ compatible label materials
- ▶ Speciality solutions like ToughWash labels and ToughStripe floor marking
- ▶ Durable labels for indoor and outdoor use
- ▶ Auto-calibration
- ▶ Automatic material set-up
- ▶ 20-second material changeovers

DESIGNED TO LAST
EXTREMELY EASY TO USE



**AUTO-CALIBRATION
AND MATERIAL
SET-UP**



**FAST MATERIAL
CHANGEOVERS**



**EASY CONNECT
PC SOFTWARE**

Printer specifications

Printer	
Description	BradyPrinter i3300 Industrial Label Printer
Colour Capability	Monocolour
Print Speed (mm/sec)	101.60
Print Resolution (dpi)	300
Internal Memory	512 MB (RAM) - 195 MB (data storage)
Size W x H x D (mm)	240 x 317 x 435
Stand-alone Printing (Detached from PC)	Peripheral
Weight (kg)	5.22
Warranty	1 year

Media	
Continuous vs Die-cut Labels	Continuous and Die-cut
Compatible Media	B30-, B30C-, B30EP-, B33-, B33C-, B33D-, B33FP-, B33FT-, B33R-
Min. Label Width (mm)	6.35
Max. Label Width (mm)	107.95
Min. Label Height (mm)	6.35
Min. Liner Width (mm)	18.03
Max. Liner Width (mm)	107.95
Max. Print Width (mm)	101.98
Recommended Usage per Day	3000

Display	
Display	Colour LCD Touchscreen
Display Resolution	320 x 240 pixels
On Screen Indicators	Supply Remaining, Ribbon Remaining, Ribbon and label part number recognition, WiFi, Ethernet Status, Error Messaging, Data Reception

Software & connectivity	
Connectivity Options	Ethernet USB USB 2.0 Wi-Fi
Software Compatibility	Brady Workstation Windows based driver for 3rd party software use

Compliance	
Approval/Compliance	UL; cUL; CE; RoHS; RCM; KCC; EAC



Printer



Article No.	Order Ref.	Description
149553	i3300-C-EU	i3300 Industrial Label Printer- EU*
322883	i3300-C-EU-BWS	i3300 Industrial Label Printer- EU + Brady Workstation Suite**
149555	i3300-300-C-UK	i3300 Industrial Label Printer- UK*
322884	i3300-C-UK-BWS	i3300 Industrial Label Printer- UK + Brady Workstation Suite**
149551	i3300-300-C-US	i3300 Industrial Label Printer- US*
322885	i3300-C-US-BWS	i3300 Industrial Label Printer- US + Brady Workstation Suite**
149554	i3300-C-EU-WF	i3300 Industrial Label Printer with Wifi- EU*
322887	i3300-C-EU-W-BWS	i3300 Industrial Label Printer with Wi-Fi - EU + Brady Workstation Suite**
149556	i3300-300-C-UK-WF	i3300 Industrial Label Printer with Wi-Fi- UK*
322888	i3300-C-UK-W-BWS	i3300 Industrial Label Printer with Wi-Fi- UK + Brady Workstation Suite**
149552	i3300-300-C-US-WF	i3300 Industrial Label Printer with Wi-Fi - US*
322889	i3300-C-US-W-BWS	i3300 Industrial Label Printer with Wi-Fi- US + Brady Workstation Suite**



**BRADY
WORKSTATION
BASIC
DESIGN**

* **BRADY WORKSTATION BASIC DESIGN:**
Ships with the free Brady Workstation Basic Design suite that includes fundamental apps and features to create labels.



**BRADY
WORKSTATION
ADVANCED
SUITE**

****BRADY WORKSTATION ADVANCED SUITE:**
Product & Wire Identification, Safety & Facility Identification, or Lab Identification, enabling easy creation of a wide range of labels and signs.

Accessories

Article No.	Order Ref.	Description
036612	Squeegee	Squeegee
120994	B30-TROLLEY	Trolley for BBP3x, S3xxx, i3300
133251	PCK-6	Printer Cleaning Kit, Thermal Transfer Printers
142114	B31-WIPER	Media Wiper 5 Pack
142116	B31-CCT	Cutter Cleaning Tool for BBP30, BBP31, BBP33, S3100 and i3300 printer
999834	Supplies Carrying Case	Supplies Carrying Case

