


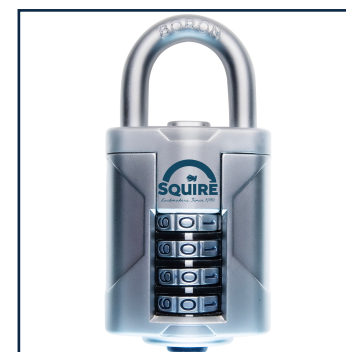

# VULCAN COMBI 40

- 40mm die cast alloy padlock body with satin chrome finish
- Weather resistant protective cover
- Double locking
- Hardened boron steel shackle with satin chrome finish
- Available with standard shackle, long shackle & closed shackle
- Fully recodable 4-wheel dial with 10,000 possible combinations
- Patented push button opening
- Easy to use with no keys to lose
- Suitable for indoor & outdoor use
- Squire security rating: Medium



| Product Name        | Body Width | Body Thickness | Shackle Diameter | Vertical Clearance | Horizontal Clearance | Approx. Height | Approx. Weight |
|---------------------|------------|----------------|------------------|--------------------|----------------------|----------------|----------------|
| VULCAN COMBI 40     | 40 mm      | 22 mm          | 6 mm             | 20 mm              | 17 mm                | 71 mm          | 0.14 kg        |
| VULCAN COMBI 40/2.5 | 40 mm      | 22 mm          | 6 mm             | 63 mm              | 17 mm                | 113 mm         | 0.16 kg        |
| VULCAN COMBI 40CS   | 40 mm      | 22 mm          | 6 mm             | 17 mm              | 13 mm                | 71 mm          | 0.17 kg        |