


**Flush-mounted Inserts**

Data communication

Data-connection box, RJ 45, cat. 6a iso, shielded

2 x outlets, 8/8-pole

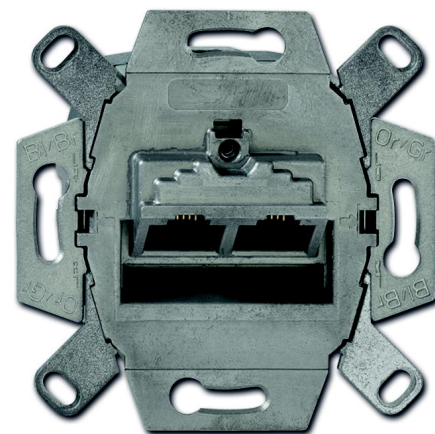

With down-leading outlet and LSA self-cutting clamps.

RJ-45 terminals for networks according to Cat 6A, Class EA (10 Gbits/s / 500MHz).

Equates to cat. 6a, Class EA according to ISO/IEC 11801:2011-06.

Terminal marking A and B according to TIA/EIA-568-B.2.

Typ according to EN 60 603-7-51:2011-01.

Shielding according to DIN EN 55022, Class B.

Up to 500 MHz on all pairs of wires.

Suitable for 10-Gigabit Ethernet.

Suitable for PoE+ according to IEEE 802.3at, >- 1.000 contact durability.

Flex cable entries from all sides without buckles.

Earthing of housing via 6,3 mm blade terminal at the back possible.

Re-embedded proofed.

Suitable for Mix-and-Match operation.

Suitable for RJ 11, RJ 12 und RJ 45.

For data cables with a diameter of 6 -10 mm.

For trunk systems, flush-mounted wall boxes and underfloor systems.

For wires of AWG 24-22.

Without claws.

Mounting depth: 31 mm.

Suitable for cover plate 1803-02-xxx.

Order Code : 0230-0-0412

Article No. : 0218/12-101-507

EAN: 4011395163887