

Product
Area Male cable connector, green
Snap-in connectors IP 67


serie 720

Pole 12
Article number 99 9133 72 12


illustration




scale drawing

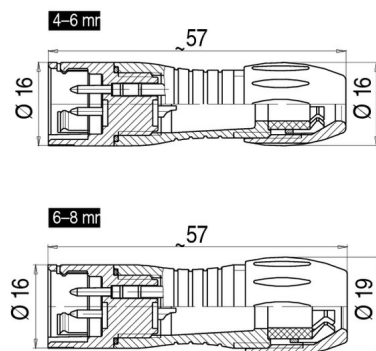

Item description

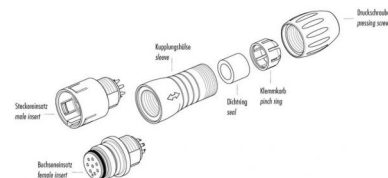

Contact Arrangement

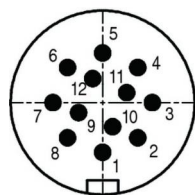

	X	Y
1	0,00 -3,70	
2	2,62 -2,62	
3	3,70 0,00	
4	2,62 2,62	
5	0,00 3,70	
6	-2,62 2,62	
7	-3,70 0,00	
8	-2,62 -2,62	
9	-1,79 -0,74	
10	0,74 -1,79	
11	1,79 0,74	
12	-0,74 1,79	

Technical data

Common values

Connector Design	Male cable connector
Connector locking system	Snap-in locking
Termination	solder
Wire gauge (mm)	0,25 mm ²
Wire gauge (AWG)	24
Max. Cable outlet	6 - 8 mm
Upper temperature	+85 °C
Lower temperature	-25 °C

Material

Material of contact	CuZn (brass)
Contact plating	Au (gold)
Material of contact body	PA (UL 94 V-0)
Material of housing	PA (UL 94 V-0)

Cable data

Contacts 12, male cable connector, green,
cable outlet 4 - 6 mm

Electrical values

Rated voltage	60 V
Rated impulse voltage	800 V
Pollution degree	2
Overvoltage category	II
Material group	II
Rated current (40°C)	2 A
Volume resistivity	≤ 3 mΩ
EMV compliance	not shielded
Degree of protection	IP 67
Mechanical operation	>500 mating cycles

