



Brand of NTN corporation

Technical data

USPFL201

Bearing units




Sheet metal housing, radial insert ball bearing with socket set screws, single lip seal

KIT CONTENT

US.201.G2, PFL203

VISUAL (S)

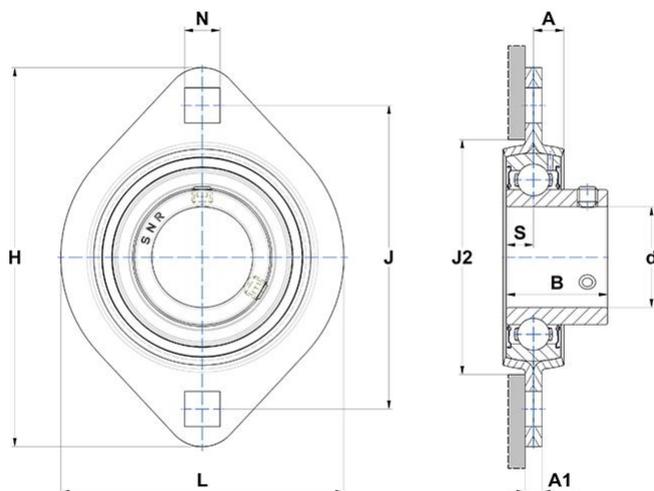

PRODUCT DEFINITION

Brand	SNR
A - Housing height	6,7 mm
A1 - Housing foot height / flange height	4 mm
A2 - Total height from mounting surface	18 mm
B - Width of Inner Ring	22 mm
d - Shaft diameter	12 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

e - Distance mounting surface to bearing center	2 mm
H - Housing length, width or diameter	81 mm
J - Mounting holes distance	63,5 mm
L - Housing width / diameter	58,7 mm
N - Mounting hole dimension	7,1 mm
S - Distance front side/bearing centre	6 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	9550000 mN
C0 - Static load rating	4780000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	0,17 kg
Recommended tightening torque for set screw	3.5 N-m

