

IN SERIES ADAPTORS

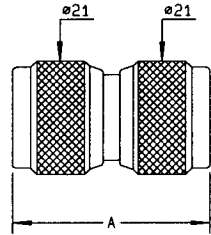
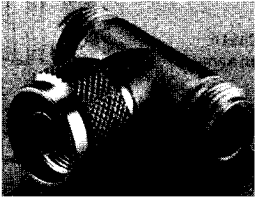


Fig. 1

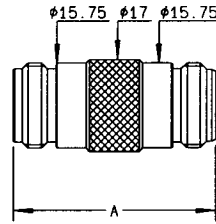


Fig. 2

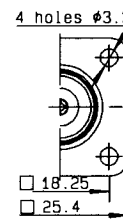


Fig. 3

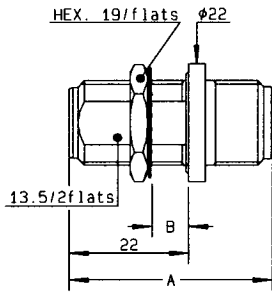


Fig. 4

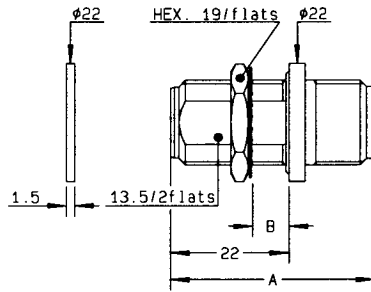


Fig. 5

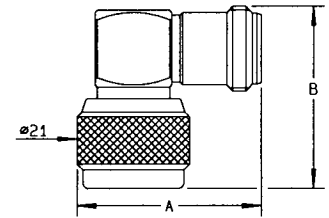


Fig. 6

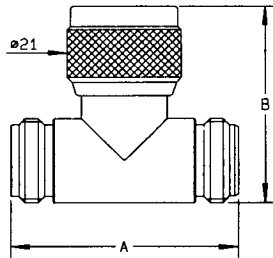


Fig. 7

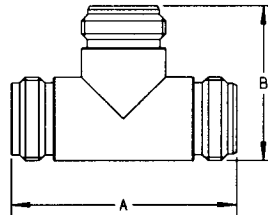


Fig. 8

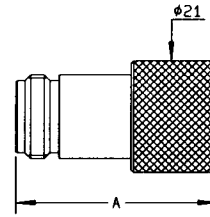


Fig. 9


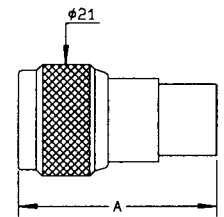



Fig. 10

part number	fig.	dimensions (mm)		panel	note
		A	B		
R161 703 000	1	36.7			M - M
R161 705 000	2	37.5			F - F
R161 715 000	3	37.5		P01	F - F / Flange
R161 730 000	4	37.5	6.5	P10	F - F / Bulkhead panel sealed
R161 753 000	5	38	6.5	P10	F - F / Hermetic / bulkhead
R161 771 000	6	34.4	34		M - F / Right-angle
R161 780 000	7	42	36.9		TEE F - F/M
R161 782 000	8	42	29.1		TEE F - F/F
R161 791 500	9	37.12			Slide - on / male sliding - female screwing
R161 791 530	10	37.12			Slide - on / male screwing - female sliding

 Note : standard packaging = 50 pieces. For unit packaging, add "W" after the P/N.




P01

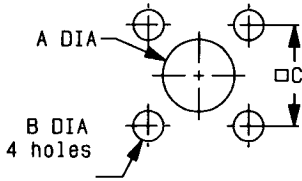


	MM		INCH	
	maxi	mini	maxi	mini
A	16.3	16.1	0.642	0.634
B	3.30	3.20	0.13	0.126
C	18.35	18.15	0.722	0.715

P02

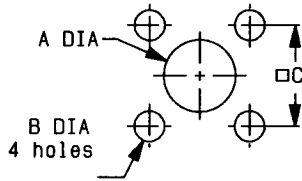


	MM		INCH	
	maxi	mini	maxi	mini
A	15.1	14.9	0.594	0.587
B	3.30	3.20	0.13	0.126
C	18.35	18.15	0.722	0.715

P03

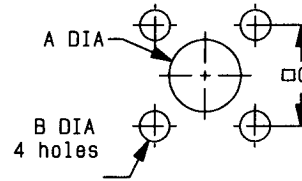


	MM		INCH	
	maxi	mini	maxi	mini
A	9.40	9.20	0.37	0.362
B	3.30	3.20	0.13	0.126
C	12.8	12.6	0.504	0.496

P04

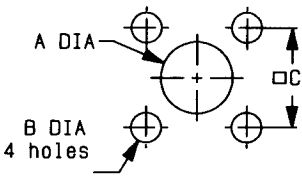


	MM		INCH	
	maxi	mini	maxi	mini
A Front	21.7	21.5	0.854	0.846
A Rear	19.7	19.5	0.776	0.768
B	3.30	3.20	0.13	0.126
C	18.35	18.15	0.722	0.715

P05

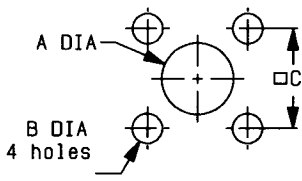


	MM		INCH	
	maxi	mini	maxi	mini
A Front	16.3	16.1	0.642	0.634
A Rear	18	17.8	0.709	0.701
B	3.30	3.20	0.13	0.126
C	18.35	18.15	0.722	0.715

P06

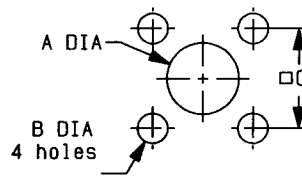


	MM		INCH	
	maxi	mini	maxi	mini
A Front	16.3	16.1	0.642	0.634
A Rear	19.7	19.5	0.776	0.768
B	3.30	3.20	0.13	0.126
C	18.35	18.15	0.722	0.715

P07

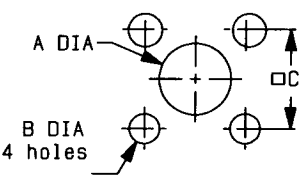


	MM		INCH	
	maxi	mini	maxi	mini
A Front	16.3	16.1	0.642	0.634
A Rear	15.1	14.9	0.594	0.587
B	3.30	3.20	0.13	0.126
C	18.35	18.15	0.722	0.715

P08

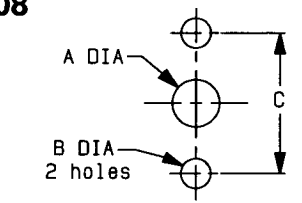


	MM		INCH	
	maxi	mini	maxi	mini
A	5	4.80	0.197	0.189
B	3.30	3.20	0.13	0.126
C	18.1	17.9	0.713	0.705

P09

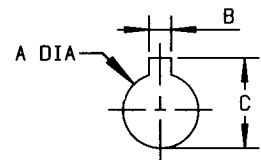


	MM		INCH	
	maxi	mini	maxi	mini
A	14.3	14.1	0.563	0.555
B	2.30	2.20	0.091	0.087
C	17	16.8	0.669	0.661

 P10




	MM		INCH	
	maxi	mini	maxi	mini
A	16.1	16	0.634	0.63
B	13.7	13.6	0.539	0.535

P11

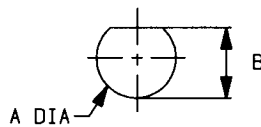


	MM		INCH	
	maxi	mini	maxi	mini
A	14.3	14.1	0.563	0.555
B	13.8	13.6	0.543	0.535


P12

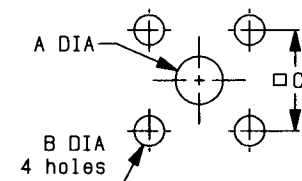

	MM		INCH	
	maxi	mini	maxi	mini
A	1.45	1.35	0.057	0.053
B	3.23	3.13	0.127	0.123
C	10.21	10.11	0.402	0.398

 


P13

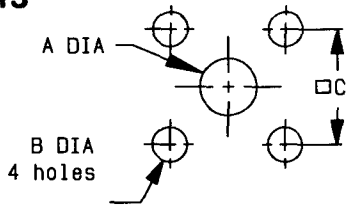


	MM		INCH	
	maxi	mini	maxi	mini
A	4.2	4.1	0.165	0.161
B	2.7	2.6	0.106	0.102
C	8.69	8.59	0.342	0.338

P14

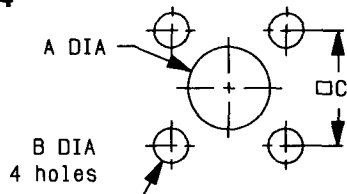


	MM		INCH		
	maxi	mini	maxi	mini	
A	Front	16.3	16.1	0.642	0.634
	Rear	12.5	12.3	0.492	0.484
B	3.3	3.2	0.13	0.126	
C	18.35	18.15	0.722	0.715	

P15

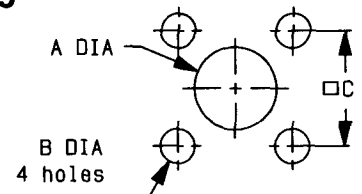


	MM		INCH		
	maxi	mini	maxi	mini	
A	Front	16.3	16.1	0.642	0.634
	Rear	4.2	4.1	0.165	0.161
B	3.3	3.2	0.13	0.126	
C	18.35	18.15	0.722	0.715	

P16

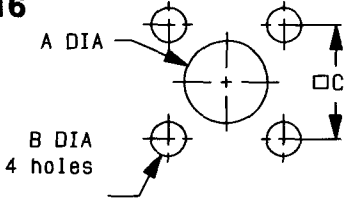


	MM		INCH	
	maxi	mini	maxi	mini
A	29.5	29.3	1.161	1.153
B	3.7	3.6	0.146	0.142
C	24.8	24.7	0.976	0.972

P17

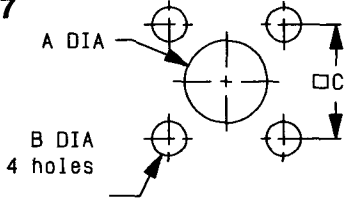


	MM		INCH	
	maxi	mini	maxi	mini
A	12.5	12.3	0.492	0.484
B	3.3	3.2	0.13	0.126
C	18.35	18.15	0.722	0.715

P18

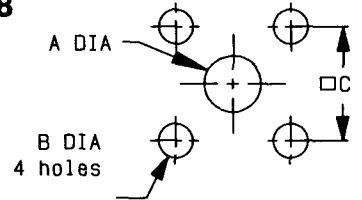


	MM		INCH	
	maxi	mini	maxi	mini
A	4.2	4.1	0.165	0.161
B	3.3	3.2	0.13	0.126
C	18.35	18.15	0.722	0.715

P19

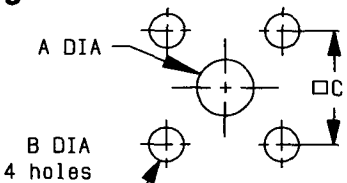


	MM		INCH	
	maxi	mini	maxi	mini
A	7.1	7	0.279	0.275
B	3.4	3.3	0.134	0.13
C	18.35	18.15	0.722	0.715

P20

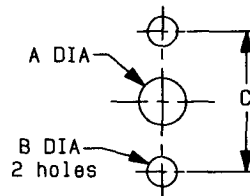


	MM		INCH	
	maxi	mini	maxi	mini
A	4.2	4.1	0.165	0.161
B	2.7	2.6	0.106	0.102
C	12.25	12.15	0.482	0.478

P21

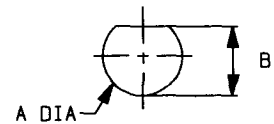


	MM		INCH	
	maxi	mini	maxi	mini
A	13	12.8	0.511	0.504
B	12.1	11.9	0.476	0.468

P22

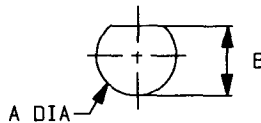

	MM		INCH	
	maxi	mini	maxi	mini
A	16.1	15.9	0.633	0.626
B	15.1	14.9	0.594	0.586

P23

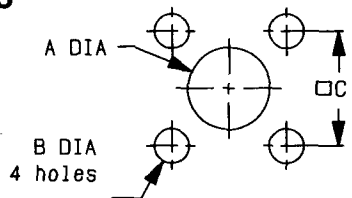

	MM		INCH		
	maxi	mini	maxi	mini	
A	Front	32.4	32.2	1.276	1.267
	Rear	16.4	16.2	0.646	0.638
B	6.6	6.5	0.26	0.256	
C	36.6	36.4	1.441	1.433	