


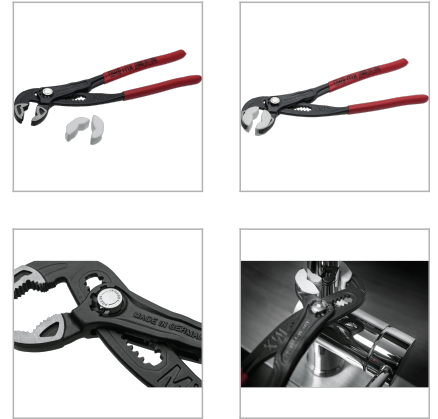

## Waterpump Pliers Maxi MX

- | The maximum water pump pliers for easy and safe work
- | Compact, narrow shape for working in smallest spaces in positions otherwise inaccessible
- | Double-toothed jaws
- | With mounting for optionally available plastic jaws, for gentle installation
- | With Nail- & wire holder
- | Optimum jaw geometry with self-locking serration
- | Gripping capacity 40% above ISO by means of arch-shaped pitch adjustment
- | Cogs additionally induction hardened
- | CurveGripp adjustment with fine teeth for a quick and safe adoption to the workpiece
- | Finger trap protection for safe work, prevents injuries caused by squeezing
- | Box joint with wide guide surfaces
- | Quick precise adjustment and release by pressing the button
- | Ergonomic handle position and shape for optimum power transmission
- | Handles coated with plastic
- | Made of special tool steel, forged, oil-hardened

SKU: 1660-12-300-SB

### General Information

#### Waterpump Pliers

"Made in Germany" is a label of quality, accuracy and experience. All these factors play a role in the production of our water pump pliers. All these wrenches are hardened and tempered, drop-forged from chrome vanadium steel and are thus well-suited to the highest demands over long service lifetimes. To ensure safe working, the jaws of the wrenches are double-toothed, the gripping teeth additionally induction-hardened and the tools have an integrated anti-pinch mechanism.



## Prepared for anything

For many heating engineers and plumbers, the exception proves to be the rule – for example, when they are called to deal with burst water pipes. They do not know in advance what to expect. But with the right selection of versatile tools, every problem becomes a routine task. The NWS tool compilation provides the plumber with tools that are just right and durable for every occasion. And if they need to get to grips with large-diameter pipes, they can do just that with the ClassicPlus.

## Downloads

|                                                                                     |                                          |                                                                                     |                                   |                                                                                       |                                   |
|-------------------------------------------------------------------------------------|------------------------------------------|-------------------------------------------------------------------------------------|-----------------------------------|---------------------------------------------------------------------------------------|-----------------------------------|
|  | NWS_VKU-0116<br>170216_Maxi MX<br>A4.pdf |  | 1660-12-250.jpg                   |  | detail_1660-12-250_1611171131.jpg |
|  | detail_1660-12-250_1611171129.jpg        |  | detail_1660-12-250_1703301326.jpg |  | detail_1660-12-250_1611121745.jpg |
|  | detail_1660-12-250_1611171136.jpg        |  | detail_1660-12-250_1704181310.jpg |  | VP-1431.jpg                       |

## Technical Data

1660-12-300-SB

|    |             |     |
|----|-------------|-----|
| ◀▶ | Length - mm | 300 |
| ◀▶ | Length - in | 12  |

|                                                                                     |                                                  |                  |
|-------------------------------------------------------------------------------------|--------------------------------------------------|------------------|
|    | Pipe - Ø mm                                      | 55               |
|    | Pipe - Ø in                                      | 2                |
|    | Wrench size - mm                                 | 65               |
|    | Spannweite - mm                                  | 75               |
|    | Teeth hardness - HRC                             | 55 - 57          |
|    | DIN standards - National, European and worldwide | DIN ISO 8976     |
|    | Weight - g                                       | 545              |
|    | Length including self-service packaging - mm     | 335              |
|    | Width including self-service packaging - mm      | 65               |
|    | Height including self-service packaging - mm     | 17               |
|    | Weight self-service packaging - g                | 15               |
|   | Packing unit                                     | 6                |
|  | Barcode                                          | 40 03758 66620 3 |