

2317070-1 ✓ ACTIVE

AMP | HDSCS


TE Internal #: 2317070-1

TE Internal Description: SLIDE,HDSCS,PIN HSG ASSY

[View on TE.com >](#)



Connectors > Automotive, Truck, Bus, & Off-Road Connectors > Connector Accessories > Other Connector Accessories

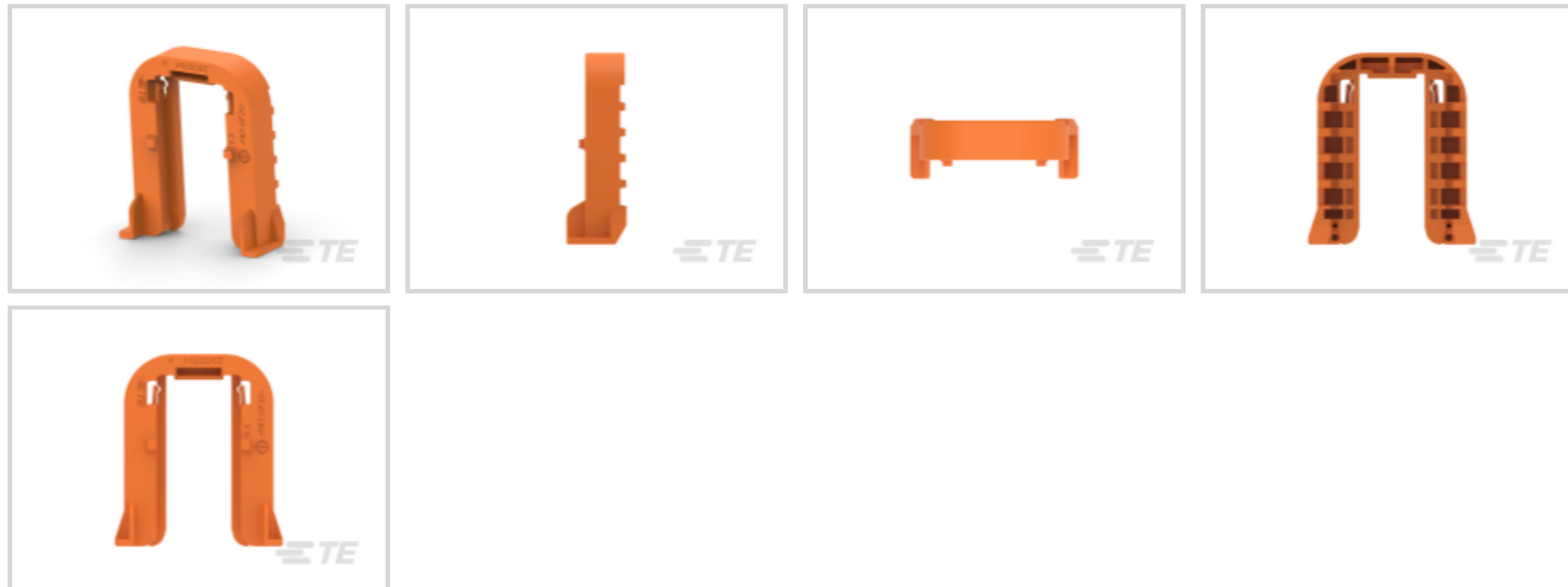

Accessory Type: **Slide**

Material: **PBT GF**

Color: **Orange**

Number of Positions: **0**

Sealable: **No**

Features

Product Type Features

Accessory Type	Slide
Sealable	No

Configuration Features

Number of Positions	0
---------------------	---

Body Features

Material	PBT GF
Color	Orange

Usage Conditions

Operating Temperature Range	-40 – 140 °C
-----------------------------	--------------

Operation/Application

Circuit Application	Signal
---------------------	--------

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

--	--

Packaging Method	Box
------------------	-----

Other

Serviceable	Yes
-------------	-----

Product Compliance


[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Not Yet Reviewed
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUL 2019 (201) Candidate List Declared Against: JAN 2019 (197) Does not contain REACH SVHC
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUL 2019 (201) Candidate List Declared Against: JAN 2019 (197)
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulations, TE's information on SVHC in articles for this part number is still based on the European Chemical Agency (ECHA) 'Guidance on requirements for substances in articles' (Version: 2, April 2011), applying the 0.1% weight on weight concentration threshold at the finished product level. TE is aware of the European Court of Justice ruling of September 10th, 2015 also known as O5A (Once An Article Always An Article) stating that, in case of 'complex object', the threshold for a SVHC must be applied to both the product as a whole and simultaneously to each of the articles forming part of its composition. TE has evaluated this ruling based on the new ECHA "Guidance on requirements for substances in articles" (June 2017, version 4.0) and will be updating its statements accordingly.

Compatible Parts

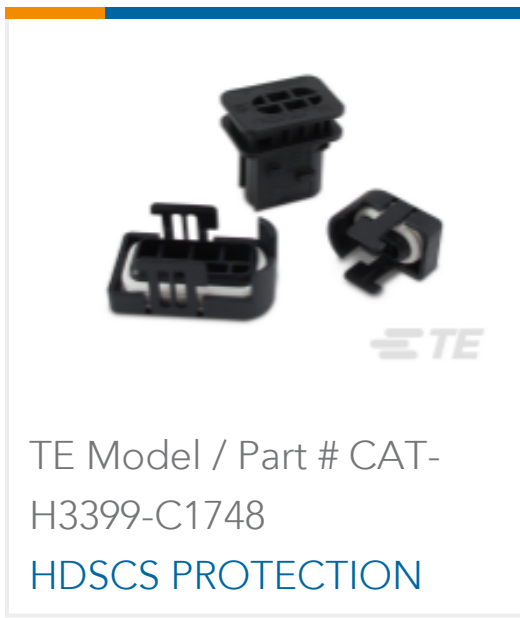

TE Model / Part # CAT-H3399-C1748
HDSCS PROTECTION CAPS



TE Model / Part # CAT-H3399-CH8172
HDSCS HOUSINGS

Also in the Series | HDSCS



Automotive Connector Caps & Covers(19)



Automotive Seals & Cavity Plugs(1)




Automotive, Truck, Bus, & Off-Road Housings(189)



Other Automotive Connector Accessories(22)

Customers Also Bought

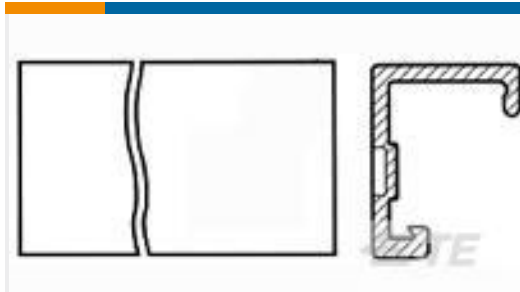


TE Model / Part #1-640551-4
14P MTA156 COVER



TE Model / Part # YHC5902000000000000
BATTERY POST CLAMP.+VE.



TE Model / Part #4-643818-4
14P MTA156 CONN ASSY 20AWG YEL

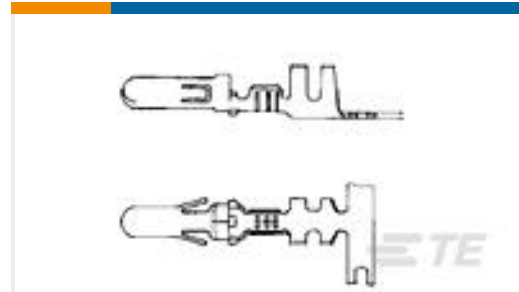

TE Model / Part #926988-2
MNL STIFT 3,5 MM



TE Model / Part #HC5843
LEAD CONN. FOR HC5840 & HC58



TE Model / Part # YHC5932000000000000
BATTERY LEAD CONNECTOR.35MM.+VE. M6 THRD.

Documents

[Product Drawings](#)
SLIDE,HDSCS,PIN HSG ASSY

English

[CAD Files](#)
3D PDF

3D



Customer View Model

[ENG_CVM_CVM_2317070-1_A.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2317070-1_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2317070-1_A.3d_stp.zip](#)

English

Datasheets & Catalog Pages

[HDSCS Catalog](#)

English