

Edge Protection Grommets

Features and Benefits


HellermannTyton edge protection grommets, made of cadmium-free, flexible PVC or Polyethylene, come in a wide range of shapes and sizes. They are resistant to various minerals and environmental effects.


Application

Edge protection grommets are used wherever cable and wires are routed through outlets and apertures. HellermannTyton grommets offer excellent mechanical protection.




Edge protection grommets.


Material Data		
	Material	Flexible Polyvinyl Chloride, cadmium free (PVC)
	Flammability	UL94 V2
	Operating Temperature	-30 °C to +60 °C
	Shore Hardness A	56±5

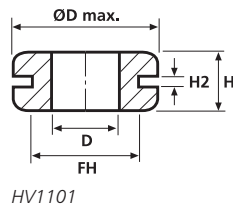


HV1101

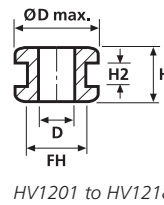


HV1201 to HV1218

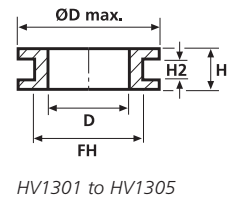


HV1301 to HV1305

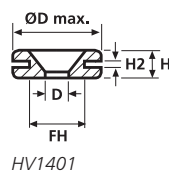


HV1401

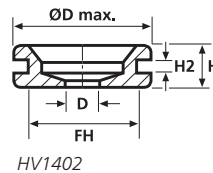


HV1402

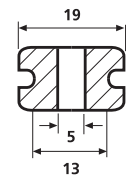

HV1606 to HV1608

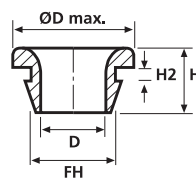

HV1502 and OP1503

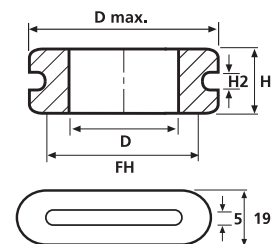

Edge Protection Grommets



Edge protection grommets.

Technical Table

Article-No.	Type	Ø D max.	Fixing Hole Ø (FH)	Ø D	Height (H)	Height (H2)	Material	Colour
633-01010	HV1101	25.5	19.0	12.0	10.0	1.6	PVC	Black (BK)
633-02010	HV1201	9.5	6.4	4.0	5.6	1.6	PVC	Black (BK)
633-02020	HV1201B	9.5	6.4	4.0	6.5	2.5	PVC	Black (BK)
633-02030	HV1203	17.5	12.0	10.0	6.8	2.0	PVC	Black (BK)
633-02040	HV1204	17.5	12.0	10.0	8.8	4.0	PVC	Black (BK)
633-02050	HV1205	17.5	13.5	10.0	8.7	4.0	PVC	Black (BK)
633-02060	HV1206	17.5	12.0	10.0	10.8	6.0	PVC	Black (BK)
633-02070	HV1207	14.0	10.0	6.0	6.4	1.5	PVC	Black (BK)
633-02080	HV1208	14.0	9.5	8.0	8.0	1.5	PVC	Black (BK)
633-02089	HV1208	14.0	9.5	8.0	8.0	1.5	PVC	White (WH)
633-02090	HV1209	11.0	9.0	4.0	5.5	1.5	PVC	Black (BK)
633-02100	HV1210	15.0	9.0	6.0	10.5	2.0	PVC	Black (BK)
633-02120	HV1212	9.0	6.0	4.0	7.0	1.0	PVC	Black (BK)
633-02150	HV1215	10.0	8.0	6.0	5.0	1.0	PVC	Black (BK)
633-02160	HV1216	14.5	8.0	5.0	6.5	1.5	PVC	Black (BK)
633-02180	HV1218	14.0	10.0	6.0	9.0	4.0	PVC	Black (BK)
633-03010	HV1301	15.9	11.0	8.0	7.0	1.0	PVC	Black (BK)
633-03019	HV1301	15.9	11.0	8.0	7.0	1.0	PVC	White (WH)
633-03020	HV1302	15.9	11.0	8.0	9.0	3.0	PVC	Black (BK)
633-03030	HV1303	15.9	11.0	8.0	6.4	1.6	PVC	Black (BK)
633-03040	HV1304	15.9	11.0	8.0	10.8	6.0	PVC	Black (BK)
633-03050	HV1305	24.0	18.0	14.0	7.0	3.0	PVC	Black (BK)
633-03059	HV1305	24.0	18.0	14.0	7.0	3.0	PVC	White (WH)
633-04010	HV1401	15.9	9.5	5.0	4.8	0.8	PVC	Black (BK)
633-04020	HV1402	23.0	18.5	6.0	7.0	2.0	PVC	Black (BK)
633-06068	HV1606	31.0	25.0	17.0	11.0	3.0	PVC	Grey (GY)
633-06078	HV1607	43.0	37.0	29.0	11.0	3.0	PVC	Grey (GY)
633-06088	HV1608	58.0	52.0	44.0	11.0	3.0	PVC	Grey (GY)
633-05020	HV1502	11.5	8.0	6.5	8.0	1.5	PVC	Black (BK)

All dimensions in mm. Subject to technical changes.