


KEMET Part Number: SN5-400
(UALSN540000000)

KEMET, SN, AC Line Filters, Normal Mode, 48 uH, MIN

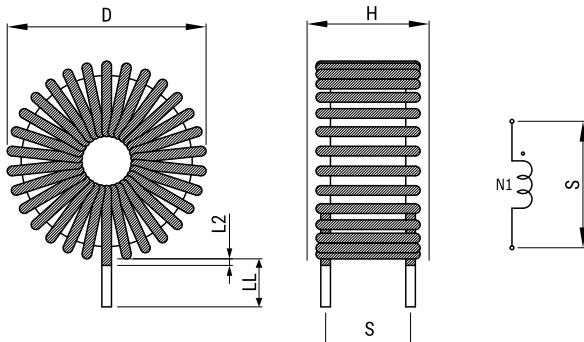

Dimensions

D	13mm MAX
H	8mm MAX
LL	20mm +/-2mm
S	6mm NOM
L2	1.5mm MAX

Packaging Specifications

Packaging:	Bulk
Packaging Quantity:	4800
Weight:	3 g

General Information

Series:	SN
Style:	Through-Hole
Features:	Compact Size
RoHS:	Yes
Miscellaneous:	22 (K) Temperature Rise Max.

Specifications

Inductance:	48 uH (0.1 MHz)
Inductance Tolerance:	MIN
Current:	2 A
Temperature Range:	-25/+105°C
DC Resistance:	58 mOhms