


Technical data sheet

Article number:

111-05404

T50L

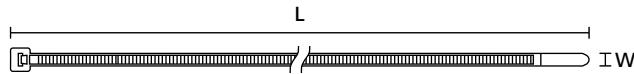

Product Group	Cable Ties Polyamide 6.6 standard
Product Family	T-Series in PA66 coloured
Material	Polyamide 6.6 (PA66)
Colour	Blue (BU)
Application Tool	ProCut 9 no battery, MK3PNSP2, EVOcut, MK7P, MK10-SB, MK20, EVO7, EVO7SP, EVO7i, EVO7iSP, EVO9, EVO9SP, EVO9i, EVO9iSP, EVO9iHT
Bundle Ø max.	110 mm
Bundle Ø min.	1.5 mm
Flammability	UL 94 V2
Halogen-free	Yes
Length (L)	390.0 mm
Min.Tensile Strength	225 N
Operating Temperature	-40 °C to +85 °C
Package Content	100 pcs.
Package Content packed in	bag
Releasable Closure (Yes/No)	No
Specifications	IEC 60092 series
Thickness (T)	1.4 mm
Toothing (Serration)	Inside Serrated
UV-Stabilised	No
Variant	Inside Serrated
Weight/Unit	0.0027 kg
Width (W)	4.6 mm

