

Impact Drill

GSB 13 RE Professional

Compact power – The most compact and powerful impact drill in its class

- ▶ Robust and powerful 600 W motor
- ▶ Extremely handy: no bigger than a glove and 1.7 kg light
- ▶ Soft in line grip for a secure hold


Other features

- ▶ Speed trigger with electronic control for exact pilot drilling
- ▶ Rotating brush plate for constant power in reverse and forward rotation
- ▶ Higher dynamic load rated ball bearing for long life
- ▶ Auxiliary handle with depth stop for better control



Technical data	
Order number	0 601 217 ...
No-load speed	0 – 2800 rpm
Impact rate at no-load speed	0 – 44800 bpm
Drilling dia. in concrete	13 mm
Drilling dia. in steel	10 mm
Drilling dia. in wood	25 mm
Chuck capacity	1.5 – 13 mm
Scope of supply	... 1F0
Auxiliary handle (1 612 025 024)	x
Carrying case (2 605 438 607)	x
Depth stop 210 mm (1 613 001 010)	x
Keyed chuck 13 mm (2 608 571 079)	x

600 W **1.7 kg**

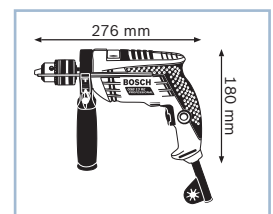

Impact Drill

GSB 16 RE Professional

Compact power – The most compact and powerful impact drill in its class

- ▶ Robust and powerful 701 W motor for tough applications
- ▶ Soft in line grip for a secure hold
- ▶ Higher dynamic load rated ball bearing for long life

Other features

- ▶ Speed trigger with electronic control for exact pilot drilling
- ▶ Speed preselection with setting wheel
- ▶ Rotating brush plate for constant power in reverse and forward rotation
- ▶ Auxiliary handle with depth stop for better control



Technical data	
Order number	0 601 218 ...
No-load speed	3000 rpm
Impact rate at no-load speed	48000 bpm
Drilling dia. in concrete	16 mm
Drilling dia. in steel	12 mm
Drilling dia. in wood	30 mm
Chuck capacity	1.5 – 13 mm
Scope of supply	... 1K0
Auxiliary handle (1 612 025 024)	x
Depth stop 210 mm (1 613 001 010)	x
Keyed chuck 13 mm (2 608 571 079)	x

701 W **1.9 kg**

