



Part Number : [1201088183](#)


Product Description : Micro-Change (M12) Double-Ended Cordset, 4 Poles, D-Coded, Male (Straight) to Male (Straight), 24 AWG, Blue TPE Cable, 25.0m (82.02') Length, 6.99mm (.275") Diameter

Series Number : 120108

Status : Active

Product Category : Circular Industrial Cordsets

Engineering Number : E11A06006M250

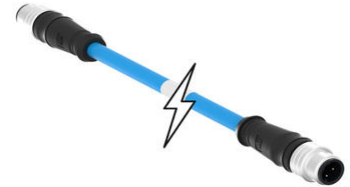

Documents & Resources

Drawings

[1201088183_sd.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|--|
| GADSL/IMDS | Not Relevant |
| China RoHS | per SJ/T 11365-2006 |
| EU ELV | Not Relevant |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21 |
| REACH SVHC | Contains Lead; TBBA; bis(2-ethylhexyl) tetrabromophthalate covering any of the individual isomers and/or combinations thereof... per D(2025)4165-DC (25 June 2025) |
| EU RoHS | Compliant with Exemption 6(c) per EU 2015/863 |

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

CE - Declaration of Conformity

UKCA - Declaration of Conformity

Part Details

General

| | |
|----------------------|--|
| Status | Active |
| Category | Circular Industrial Cordsets |
| Series | 120108 |
| Description | Micro-Change (M12) Double-Ended Cordset, 4 Poles, D-Coded, Male (Straight) to Male (Straight), 24 AWG, Blue TPE Cable, 25.0m (82.02') Length, 6.99mm (.275") Diameter |
| IP Rating | IP67 |
| Performance Category | 5e |
| Product Name | Micro-Change (M12) |
| Protocol | EtherNet |
| Type | Double Ended |
| UPC | 78172540016 |

Agency

| | |
|----|---------|
| UL | E361772 |
|----|---------|

Electrical

| | |
|-------------------------------|------|
| Current - Maximum per Contact | 1.5A |
| Voltage - Maximum | 125V |

Physical

| | |
|-------------------------------|----------------------|
| Cable Diameter | 6.99mm (.275") |
| Cable Length | 25.0m (82.02') |
| Color - Cable Jacket | Blue |
| Connector End A | Micro-Change (M12) |
| Connector End B | Micro-Change (M12) |
| Coupling Style | Threaded |
| Gender | Male-Male |
| Keyway | D-Coded |
| LED Indicator | None |
| Material - Cable Jacket | TPE |
| Material - Connector Body | PUR |
| Material - Contact | Copper Alloy |
| Material - Coupling Nut | Nickel-plated Brass |
| Material - Plating Mating | Gold |
| Net Weight | 25415.000/g |
| Orientation | Straight to Straight |
| Poles | 4 |
| Temperature Range - Operating | -20° to +75°C |
| Wire/Cable Type | Unshielded TPE |
| Wire Size (AWG) | 24 |