


HP04-05 Surface Heaters IP68

Features

- Highly effective heat transfer provided by the aluminum housing
- Available in different voltage / temperature options
- Externally tested to achieve IP68 rating
- For use in wet, dirty and harsh environments
- 2 Meter two core cable as standard
- Compact design
- Extremely forgiving against mishandling
- Self-regulating PTC heater

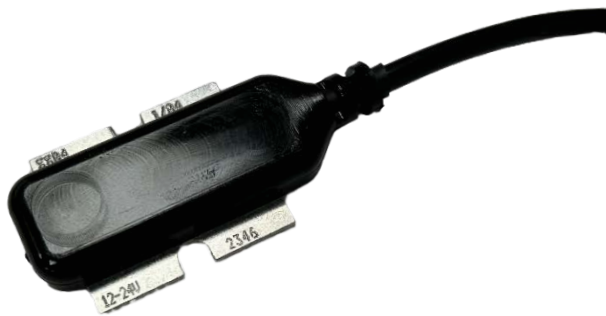

Type	Depth	Mounting Face LxW	Voltage / V	Rated Temperature ±10°C / 18°F	Part No
HP04	max 8.3mm 0.327"	40x35mm 1.57x1.38"	12-24	40°C / 104°F	040100353
				80°C / 176°F	040100354
			100-240	50°C / 122°F	040100355
				70°C / 158°F	040100356
				90°C / 194°F	040100357
				110°C / 230°F	040100530
HP05	max 8.3mm 0.327"	40x35mm 1.57x1.38"	12-24	40°C / 104°F	040100358
				100°C / 176°F	040100359
			100-240	50°C / 122°F	040100360
				70°C / 158°F	040100361
				90°C / 194°F	040100362
				110°C / 230°F	040100363

Rated Temperature is the Curie point (CP) of PTC, actual surface temperature may vary, typically approx 20°C (36°F) above CP

