


FEATURES

- Metric threads
- High mechanical strength
- Ideal for use where good insulation and corrosion resistance is required
- Suitable for use in high voltage assemblies
- Moulded from ivory coloured Nylon 6,6

RS PRO Nylon Hexagon Head Machine Screws

RS Stock No.:

2326995,2326996,2326997,2326998,
2326999,2327001,2326880,2326881,2326883,
2326888,2326884,2326882,2326889,
2326890,2326891,2326892

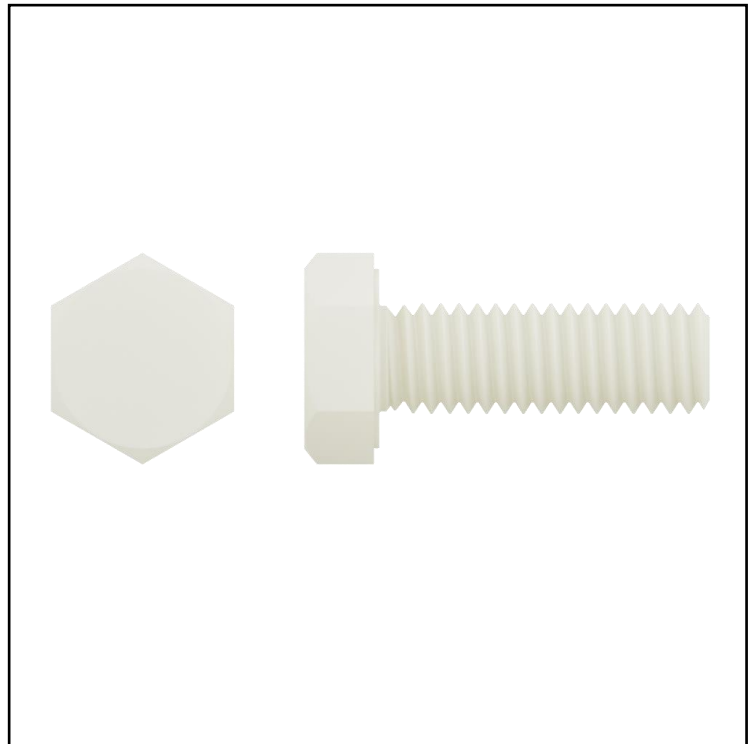

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.


Nylon Hexagon Head Machine Screws

Product Description

RS Pro machine screws are moulded from ivory coloured Nylon 6,6. This hexagon head machine screw features metric thread and high mechanical strength. The machine screw is ideal for use where good insulation and corrosion resistance is required. This screw is suitable for use in high voltage assemblies.

Material Specifications

Material	Nylon 6,6
Colour	Natural

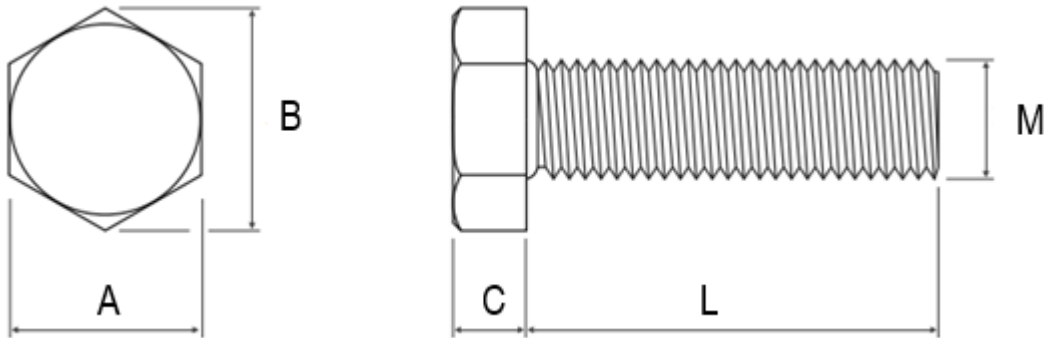

General Specifications

Thread Size (M)	RS Stock No. / Length (L)								Head Size		
	16	20	25	30	40	50	60	70	A (Across Flats)	B	C
M8 x 1.25	2326995	2326996	2326997	2326998	2326999		2327001		12.8	14.38	5.3
M10 x 1.5		2326880		2326881	2326882	2326883	2326884		17	18.9	6.4
M12 x 1.75		2326888		2326889	2326890	2326891		2326892	19	21.1	7.5

Dimensions are in millimetres (mm)

Approvals

Standards Met	DIN 933
---------------	---------