

CA-12S2N128007 - Cable connector



1627735

<https://www.phoenixcontact.com/in/products/1627735>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



M23, Cable connector, series: CA, straight, shielded: yes, Screw locking mechanism, No. of pos. : 12, Direction of rotation: Counter direction, contact connection type: Socket, Solder connection, cable diameter range: 6 mm ... 10 mm, coding: N, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1245508

Your advantages

- Safe use in the field, thanks to high degree of protection
- Connector for flexible on-site assembly
- Consistent EMC protection for reliable transmission of signals
- Solder connection: proven connection technology for various litz wires

Commercial data

Item number	1627735
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	ABR
Product key	ABRAEA
GTIN	4055626348209
Weight per piece (including packing)	94.6 g
Weight per piece (excluding packing)	91 g
Customs tariff number	85366990
Country of origin	DE

CA-12S2N128007 - Cable connector



1627735

<https://www.phoenixcontact.com/in/products/1627735>

Technical data

Product properties

Product type	Circular connector (cable-side)
--------------	---------------------------------

Connector

Insulating body

Coding	N
Insulation body material	PBT
Contact material	CuZn
Contact surface material	Ni/Au
Insertion/withdrawal cycles	100
Connection method	Solder connection
Contact switching type	Socket
Application	Signal
Number of positions	12
Direction of rotation	Counter direction
Connection profile	12
Contact diameter	1 mm
Litz wire cross-section	0.08 mm ²
Litz wire cross-section	1 mm ²
Rated current	8 A
Rated voltage	48 V AC 74 V DC
Rated surge voltage	1.5 kV
Overvoltage category	III
Degree of pollution	3

Housing

Housing material	Turned parts: copper zinc alloy (CuZn), die-cast parts: zinc (GD-Zn)
Type of locking	Screw locking mechanism
Pg screw connection	none
Degree of protection (plugged in)	IP67
Thread type	M23

Seal

External cable diameter	6 mm ... 10 mm
Seal material	NBR

Environmental and real-life conditions

Ambient conditions

CA-12S2N128007 - Cable connector

1627735

<https://www.phoenixcontact.com/in/products/1627735>



Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------

CA-12S2N128007 - Cable connector


1627735

<https://www.phoenixcontact.com/in/products/1627735>



Drawings

Schematic diagram

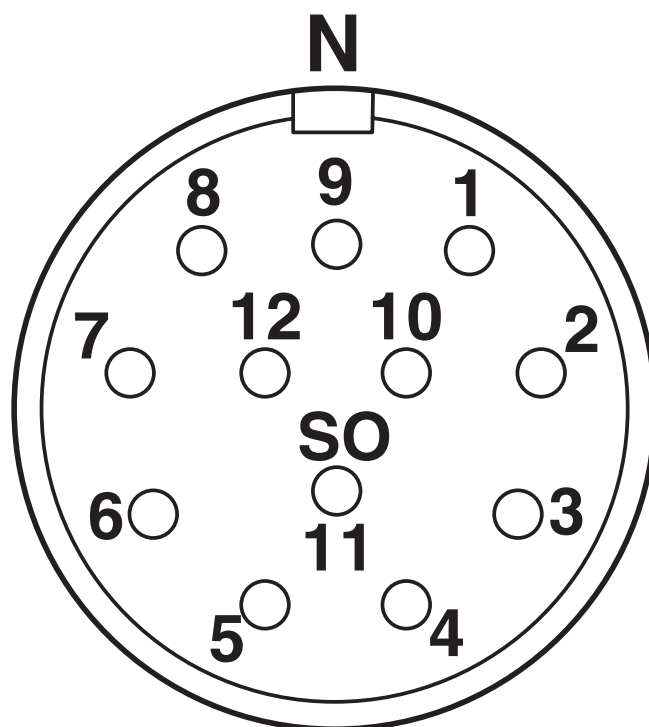

Contact chamber numbering (view of plug-in side), socket counter direction

CA-12S2N128007 - Cable connector



1627735

<https://www.phoenixcontact.com/in/products/1627735>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1627735>

cUL Recognized Approval ID: E335019-20141210				
	Nominal voltage U_N	Nominal current I_N	Cross section AWG	Cross section mm^2
	48 V	6 A	18	-

UL Recognized Approval ID: E335019-20141210				
	Nominal voltage U_N	Nominal current I_N	Cross section AWG	Cross section mm^2
	48 V	8 A	18	-

cULus Recognized				
------------------	--	--	--	--

CA-12S2N128007 - Cable connector



1627735

<https://www.phoenixcontact.com/in/products/1627735>

Classifications

ECLASS

ECLASS-11.0	27440102
ECLASS-12.0	27440116
ECLASS-13.0	27440116

ETIM

ETIM 9.0	EC002635
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

CA-12S2N128007 - Cable connector

1627735

<https://www.phoenixcontact.com/in/products/1627735>



Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)

China RoHS	
Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.

EU REACH SVHC	
REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	1b541461-ff8f-425d-bd63-2a4276c9b2a5

CA-12S2N128007 - Cable connector

1627735

<https://www.phoenixcontact.com/in/products/1627735>



Accessories

SF-Z0028 - Torque screwdriver

1607456

<https://www.phoenixcontact.com/in/products/1607456>

Torque screwdriver, series: RC, UC, SH, SF



SF-Z0027 - Hook wrench

1607455

<https://www.phoenixcontact.com/in/products/1607455>

Hook wrench, series: RC, UC, RF, SF



CA-12S2N128007 - Cable connector

1627735

<https://www.phoenixcontact.com/in/products/1627735>




RF-Z0014 - Color coding

1620588

<https://www.phoenixcontact.com/in/products/1620588>

Color coding, color: green

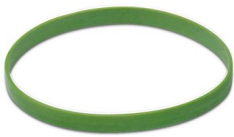

RF-Z0015 - Color coding

1620592

<https://www.phoenixcontact.com/in/products/1620592>

Color coding, color: orange



CA-12S2N128007 - Cable connector

1627735

<https://www.phoenixcontact.com/in/products/1627735>



RF-Z0016 - Color coding

1620593

<https://www.phoenixcontact.com/in/products/1620593>

Color coding, color: black



RF-Z0003 - Square mounting flange

1607905

<https://www.phoenixcontact.com/in/products/1607905>



Square mounting flange, Axial seal, 4xM3, flange dimensions: 35 mm x 35 mm, series: RF, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1242369

CA-12S2N128007 - Cable connector

1627735

<https://www.phoenixcontact.com/in/products/1627735>



CA-Z0077 - Metal protective cap

1627224

<https://www.phoenixcontact.com/in/products/1627224>



Metal protective cap, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1245447

PROT-M23-SG-IT-IP20 - Plastic protective cap

1577206

<https://www.phoenixcontact.com/in/products/1577206>



Plastic protective cap, M23, series: CA, RC, RF, UC, RM

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.
A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420
info@phoenixcontact.co.in