




STASEI 200 grau/grey

Industrial Connectors:Rectangular connectors ST-series:Panel-mounted connector

Product description

Description	Panel-mounted connector with coding fin and added gasket
Type	STASEI 200 grau/grey
Order No.	932 048-106
Type of contact	male
Number of contacts	2 + PE
Conductor size	max. 1.5 mm ²
Housing Color	grey
Contact bearer color	black

Drawing

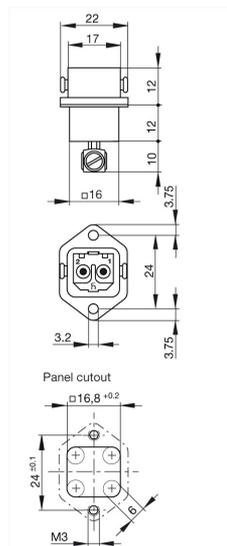

Technical data

Pin dimensions	2 mm
Rated voltage	250 V AC/DC
Rated current	DC 10 A / AC 16 A
Contact resistance	≤ 5 mOhm
Type of termination	screws

Material

Contact material	Cu Zn
Contact surface material	Sn
Contact bearer material	PA
Housing material	PA

Environmental conditions

Protection class (IEC 60529)	IP 54
Pollution severity	3
Temperature range	-30 °C to +90 °C

Inflammability class

Housing	UL 94 HB
Contact bearer	UL 94 V-1

Approvals

UL	UL
VDE	VDE
SEV	SEV
Packing unit	
Packaging unit	100 pieces
Scope of delivery and accessories	
Accessories to order separately	safety brackets STASI 2, order no. 732 044-000