
PARATHOM CLASSIC A 60 10 W/840 E27

PARATHOM CLASSIC A | LED lamps, classic bulb shape



Areas of application

- Domestic applications
- General illumination
- Outdoor applications only in suitable luminaires

Product benefits

- Long lifetime of up to 15,000 h
- Low energy consumption
- Easy replacement of classic lamps thanks to compact design
- Instant 100 % light, no warm-up time

Product features

- LED alternative to conventional lamps
- Mercury-free lamps
- Made in Germany (versions up to incl. 75 W replacement)



Technical data

Electrical data

Rated wattage	8.00 W
Nominal wattage	8.00 W
Nominal voltage	220...240 V
Operating frequency	50...60 Hz
Power factor λ	> 0.50
Claimed equiv. conventional lamp power	60 W


Photometrical data

Nominal luminous flux	806 lm
Rated luminous flux	806 lm
Color temperature	4000 K
Color rendering index Ra	≥ 80
Light color (designation)	Cool White
Standard deviation of color matching	≤ 6 sdc _m

Light technical data

Warm-up time (60 %)	≤ 1.00 s
Starting time	< 0.5 s

Dimensions & weight

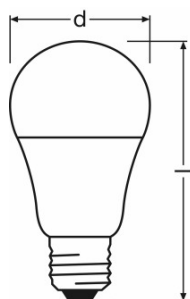

Overall length	110.0 mm
Diameter	60.0 mm
Outer bulb	A60
Length	110.0 mm

Lifespan

Product datasheet

Nominal lamp life time	15000 h
Rated lamp life time	15000 h
Number of switching cycles	100000
Lumen main.fact.at end of nom.life time	0.70
Lumen maintenance at end of service life	0.70

Additional product data

Base (standard designation)	E27
Mercury content	0.0 mg
Mercury-free	Yes
Design / version	Frosted
Appropriate disposal acc. to WEEE	Yes
Product remark	All technical parameters apply to the entire lamp/Due to the complex production process for light-emitting diodes, the typical values shown for the technical LED parameters are purely statistical values that do not necessarily match the actual technical parameters of each individual product, which can vary from the typical value/In development, data preliminary

Capabilities

Dimmable	No
----------	----

Certificates & standards

Energy efficiency class	A+
Energy consumption	8 kWh/1000h

Country specific categorizations

ILCOS	DRAA/F-10/840-230-E27-60
Order reference	PCLA60 8W/840 2

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4052899369818	PARATHOM CLASSIC A 60 10 W/840 E27	Shipping carton box 10	315 mm x 131 mm x 124 mm	5.12 dm ³	849.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

References / Links

Product datasheet

For further products and actual information concerning LED lamps see

▶ www.ledvance.com/ledlamps

For Guarantee see

▶ www.ledvance.com/guarantee

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.