

Features

- USB2.0
- USB Type A to Mini B
- 10 Pack
- 20cm in length

RS PRO USB Cables

RS Stock No.: 0354236



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

The RS PRO 20cm USB version 2.0 A male to mini B male cable has a black PVC jacket and connector hoods. The cable flex has copper wire conductors and drain wire, with an aluminium braid, foil shielding and has an outer diameter of 4mm.

The connectors are nickel and have a strain relief to help avoid the cable splitting around the edge of the boot.

USB Mini B ports are commonly found on portable devices such as phones, cameras and portable hard disks.

Supplied in a pack of 10 units

General Specifications


USB Type	USB 2.0
Connector A	USB Type A
Connector A Gender	Male
Connector B	USB Mini B
Connector B Gender	Male
Connector Style	Plug, straight
Data Transfer Rate	480 Mbps
Outer Sheath Material	PVC
Sheath Colour	Black

Mechanical Specifications

Length	20cm
Cable Specification	28AWG

Approvals

Standards Met	CE UKCA ROHS REACH
---------------	--------------------

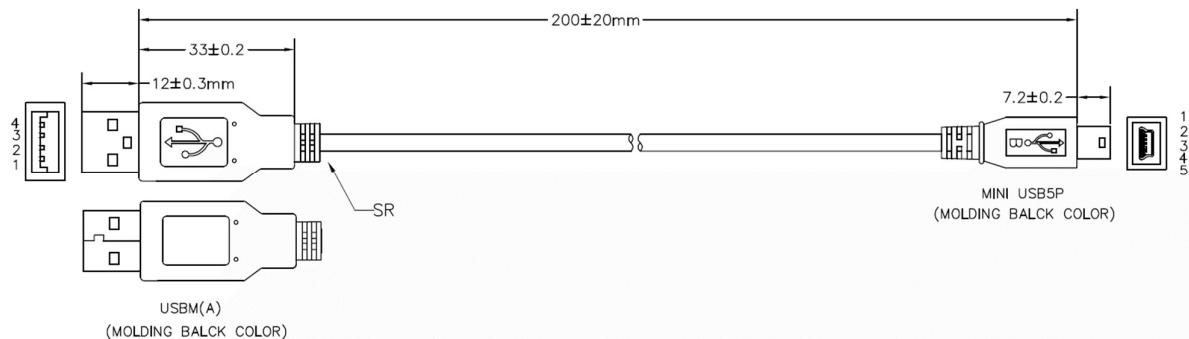

1	2	3	4	64
1	2	3	5	64
RED	WHITE	GREEN	BLACK	SHIELD
	#28	#28		
	PAIR			

1. CABLE: UL2725,AL+B-FOIL,28AWG*1P+28AWG*2C,BLACK COLOR,OD=4.0±0.2mm,PVC JACKET.
2. LENGTH: 0.2M.
3. CONNECTORS: USBM(A)*1,MINI USB5P*1(WHITE INSULATOR)(SHELL NICKEL).
4. MOLD: MOLDING USB TYPE.
5. CONTACTS
6. Test machine test condition.
 - A.100% OPEN,SHORT&INTERMITANCE TEST.
 - B.CONDUCTOR RESISTANCE: 3ohms MAX:
 - C.INSULATION RESISTANCE: 5M Min/,10ms:
7. ALL MUST BE MEET ON ROHS COMPLIANT.