

# EHA3

## Hand switch

### Benefits

- Robust ergonomic design
- Tactile buttons, clearly marked
- Easy mountable fastening hook




### Technical data

	Unit	EHA 3
Max. operating channels	n°	5
Operating power	V DC/mA	12/50
Type of protection	IP	67
Color	-	Grey
Cable: Coiled 1,3 m/2,5 m	-	D-sub 15-pin

### Dimensional drawing

High density  
D-Sub 15

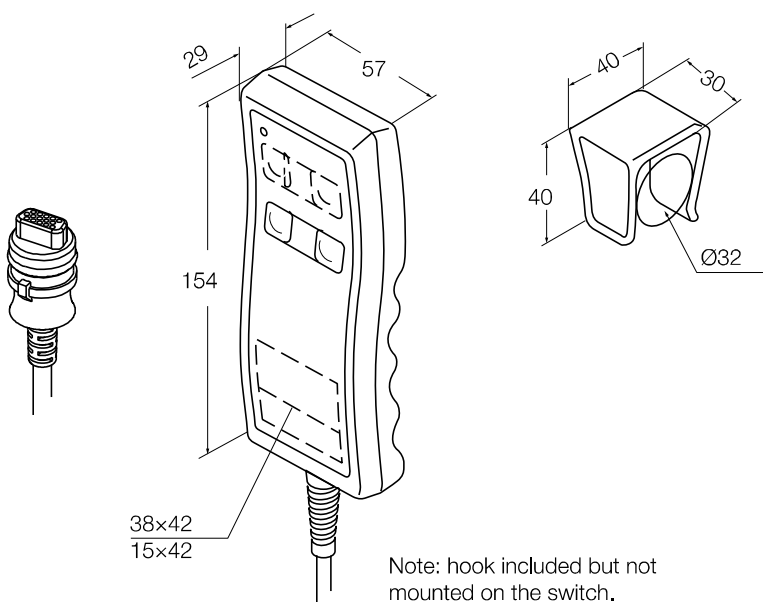

Note: hook included but not mounted on the switch.

## Suitable control units and pillars

	Pillars		Control units							
	TFG 50	TFG 90	SCU 1	SCU 5	SCU 9	VCU 5	VCU 8	VCU 9	BCU 5	BCU 8
EHA3	•	•	•	•	•	•	•	•	•	•

## Accessories

Description	Designation	Order number
Hook with sticker	ZBG-145361-000	0125538

## Ordering keys



Type

Number of channels

- 1 1 channel
- 2 2 channels
- 3 3 channels
- 4 4 channels
- 5 5 channels
- A 1 channel with 3 memory positions (only for SCU)
- B 2 channels with 3 memory positions (only for SCU)
- C 3 channels with 3 memory positions (only for SCU)

Symbols

- 00 None
- 10 1 channel: 2nd row from top      Arrow up/down
- 11    Head
- 12    Foot
- 13    Level
- 14    Anti-Trendelenburg
- 20 2 channels: 1st-2nd row from top    Arrow up/down
- 21    Head/foot
- 22    Head/level
- 23    Level/head
- 29    Level/Anti-Trendelenburg
- 30 3 channels: 1st-3rd row from top      Arrow up/down
- 31    Head/foot/level
- 32    Level/head/foot
- 39    Level/Anti-Trendelenburg/Head
- 40 4 channels: 1st-4th row from top      Arrow up/down
- 47    Level/Anti-Trendelenburg/Head/Foot
- 50 5 channels: 1st-5th row from top      Arrow up/down

■ Options shown in red are only available on demand. Please contact Ewellix.