


CXD5602PWBCAM1

Specifications & Handling Manual

Dimensions

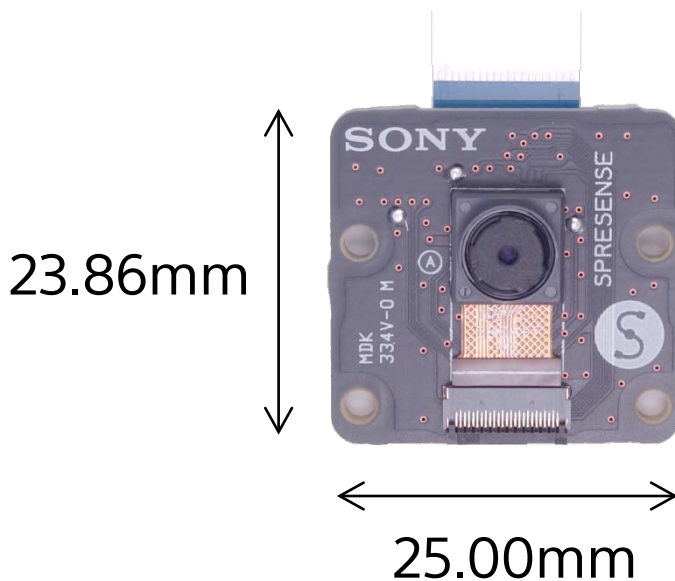

Specifications

Number of effective pixels	2608(H) x 1960 (V) = approx. 5.11 M pixels
Operation voltage	DC 3.7V
I/O voltage	DC 1.8V
Camera interface	CMOS 8 bit parallel
Control interface	I2C
Built-in filter	IR cut filter
FOV	78°±3°
Depth of field	77.5cm ~ ∞
F value	2.0±5%
Focus	Fixed focus

Precautions


Do not remove the camera module



Camera module

Do not remove the flexible cable

Do not touch the electronic parts

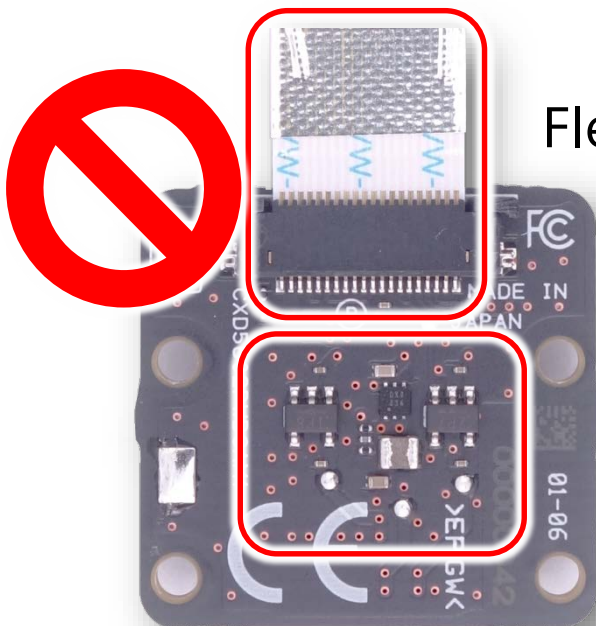

Flexible cable

Electronic parts

Connection

The camera board is connected to the main board directory. Be sure to the direction of the flexible cable

