

# INTERCONNECTION

## Easy Break Terminal Strips


- Easily snapped to required numbered of poles
- No remaining burrs
- No tools needed to cut to length
- Moulded in natural UL94-V2 self extinguishing PA6, black optional
- Supplied with screws in raised position
- 12 poles
- Halogen free

CTSOS



### SPECIFICATION

Voltage max	450V AC
Working temperature	-30°C to + 110°C
Moulding	UL94-V2 self extinguishing PA6
Insert	Nickel Plated Brass
Screws	Zinc-plated steel

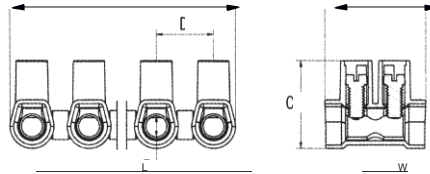

TYPE NO.	CURRENT RATING	CONNECTING CAPACITY	MIN CONDUCTOR SECTION	LENGTH	WIDTH	HEIGHT	PITCH	TERMINAL SCREW
CTSOS431	24A	2.5mm <sup>2</sup>	1mm <sup>2</sup>	95.5mm	17.5mm	14.75mm	8mm	M3
CTSOS433	41A	6mm <sup>2</sup>	2.5mm <sup>2</sup>	118mm	19mm	15.6mm	10mm	M3
CTSOS434	57A	10mm <sup>2</sup>	4mm <sup>2</sup>	142mm	20.8mm	18.2mm	12mm	M3.5
CTSOS435	76A	16mm <sup>2</sup>	6mm <sup>2</sup>	160mm	23mm	21.2mm	13.5mm	M4
CTSOS438	125A	35mm <sup>2</sup>	16mm <sup>2</sup>	176.5mm	25.5mm	28mm	15mm	M5

