


Technical data

BK1312

Drawn cup needle roller bearings, closed end

Needle roller bearing, drawn cup, closed end

VISUAL (S)

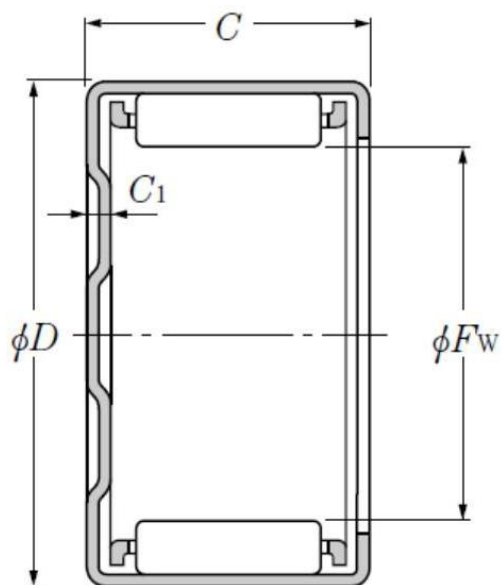

PRODUCT DEFINITION

Brand	NTN
Fw - Under rollers diameter	13 mm
D - External diameter	19 mm
C - Width of bearing, drawn cup or outer ring	12 mm
C1 - Max drawn cup closed end thickness	2,7 mm
Lubrication hole on outer ring	Non/No
Inner ring reference	IR10X13X12.5
Mass	0,011 kg



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

BK1312

Drawn cup needle roller bearings, closed end

PRODUCT PERFORMANCE

Cr - Dynamic load rating	6,95 kN
C0r - Static load rating	7,9 kN
N lim - Grease lubrication limit speed	12000 tr/min
N lim - Oil lubrication limit speed	18000 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	120 °C

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
Reference	BK1312
Image	NRBBK_1.jpg, NRBBK_3.jpg
Rolling element material	Acier 100Cr6



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15