


# Blue Elastic Rubber Trolley Wheel 160mm, stainless steel roller, 350kg

Elastic Rubber-tyred wheel

PRODUCT

Article number

571-511-160R20X

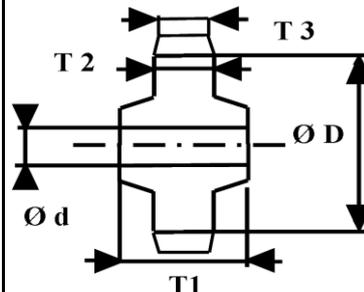

## Product Details

Wheel Rim : very thick black polyamide.  
 Tyre : solid, blue bonded elastic rubber tyre, non marking.  
 Hub : symmetrical, stainless steel roller bearing.

## Specifications

Wheel Diameter - ØD ± 1%	<b>160 mm</b>
Hub Type	<b>Stainless steel Roller Bearing</b>
Hub Length T1	<b>60 mm ±1</b>
Width of Tread T2	<b>42 mm ±1</b>
Width of Tread-on floor T3	<b>42 mm ±1</b>
Axle Hole Ø d	<b>Ø 20 mm</b>
Hardness of tread A ±4	<b>A 70 Shore</b>
Load capacity	<b>350 Kg</b>
Temperature	<b>-20 / +60 °C</b>
Weight	<b>0,75 Kg</b>

TECHNICAL DATA

## Applications :

Sensitive materials handling on uneven surfaces.  
 Resilient with a low starting effort.  
 Does not leave scratches or other marks on surfaces.  
 Reduce schok and vibration.  
 Quiet in use and high wear resistance.  
 Suitable for industrial floors and also all interior floors (catering, kitchen, humid ou corrosive environment thanks to the stainless steel roller).