



Datasheet

ENGLISH

Incoloy 825 Industrial Water Immersion Heaters



Description

A comprehensive range of industrial immersion heaters using Incoloy sheathed heating elements and adjustable rod thermostats.

Application


- Hot water heating

Key Features

- Loadings available from 3 – 12 kW
- Wired in single phase or 3 phase
- Control thermostat in Incoloy 825 pocket
- Incoloy 825 Industrial heaters with angular rotary terminal enclosure
- Immersed lengths from 11 - 30 inches
- **Sheath:** Incoloy
- **Thermostat:** All dual cut-out heaters come with rod thermostats supplied

Safety Features

- Dual cut-out
- Separate, secondary manual reset safety cut-out, fitted directly to the immersion heater head

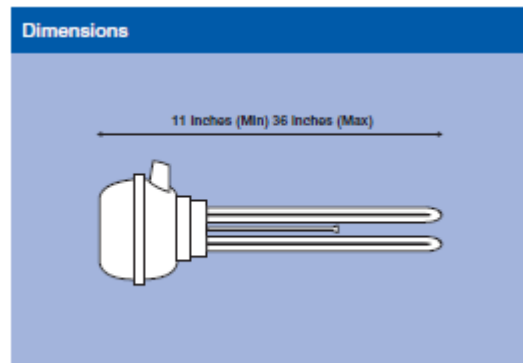

Approvals

- WRAS Approved
- BEAB Approved
- CE

Product Range

RS Pro	Loading (kW@240V)	Phases	Immersed length (inches)	Immersed length (mm)
272-996	3	1 or 3	11	279
273-006	3	1 or 3	30	762
273-012	4	1 or 3	11	279
273-028	4	1 or 3	16	406
273-034	6	1 or 3	16	406
273-040	6	1 or 3	30	762
273-056	9	1 or 3	14	356
273-062	9	1 or 3	27	686
273-135	12	1 or 3	24	610