

# Wiha single-pole voltage tester.

For both DIY and professional users.

## Single-pole voltage tester.



AC 1000V  
IEC 60900:2004

**255-3** Single-pole voltage tester, 220-250 volts.  
Acc. to DIN VDE 0680-6, GS-mark.

Blade: Slotted blade, 65 mm long.

Handle: Transparent with clip.

Application: For both DIY and professional users.

Order-No.	Ⓛ	➔	➔	➔		
00454 5	3.0	65	140	15	in pouch	10
05271 3	3.0	65	140	15	single	10



AC 1000V  
IEC 60900:2004

**SB 255-3** Single-pole voltage tester 220-250 volts in blister pack.  
Acc. to DIN VDE 0680-6, GS-mark.

Order-No.	Ⓛ	➔	➔	➔		
32201 4	3.0	65	140	15		1



AC 1000V  
IEC 60900:2004

**255-3 VB** Single-pole voltage tester 220-250 volts, 60 pcs.  
In display box.

Order-No.		
32385 1		1



AC 1000V  
IEC 60900:2004

**255-4** Single-pole voltage tester, 100-500 volts.

Blade: Slotted blade, 107 mm long.

Handle: Transparent.

Application: For both DIY and professional users.

Order-No.	Ⓛ	➔	➔	➔		
27863 2	4.0	107	200	18	in pouch	10
27862 5	4.0	107	200	18	single	10

## Single-pole voltage tester/automotive circuit tester.



AC 1000V  
IEC 60900:2004

**255-7** Single-pole voltage tester, 220-250 volts.  
Acc. to DIN VDE 0680-6, GS-mark.

Blade: Slotted blade, 70 mm long.

Handle: Black with clip.

Application: For both DIY and professional users.

Order-No.	Ⓛ	➔	➔	➔		
00456 9	3.0	70	165	17	single	10



AC 1000V  
IEC 60900:2004

**SB 255-7** Single-pole voltage tester 220-250 volts in blister pack.  
Acc. to DIN VDE 0680-6, GS-mark.

Order-No.	Ⓛ	➔	➔	➔		
31771 3	3.0	70	165	17		1



AC 1000V  
IEC 60900:2004

**255-8** Single-pole voltage tester, 220-250 volts.  
Acc. to DIN VDE 0680-6, GS-mark.

Blade: Slotted blade, 100 mm long.

Handle: Black.

Application: For both DIY and professional users.

Order-No.	Ⓛ	➔	➔	➔		
00457 6	3.5	100	185	19	single	10



AC 1000V  
IEC 60900:2004

**SB 255-8** Single-pole voltage tester 220-250 volts in blister pack.  
Acc. to DIN VDE 0680-6, GS-mark.

Order-No.	Ⓛ	➔	➔	➔		
32202 1	3.5	100	185	19		1



**258-4** Automotive circuit tester 6-24 volts.

With alligator clip, probe tip with protective cap.

Application: Ideal for automotive circuit testing.

Extra: Storage pouch supplied.

Order-No.			
00468 2	120	24 volts	10
00472 9		Replacement bulb 24 V	10

# Wiha magazine bit holder.


Eight screwdrivers in one.



reddot design award  
best of the best 2008



"Eight screwdrivers in one" is how the Wiha magazine bit holder might best be described. The bit magazine accommodated by the handle is swung open with a light press of the thumb. The bits can then be quickly and simply changed. Thanks to this new solution for storing and extracting bits, the user always has a clear idea of where things are.

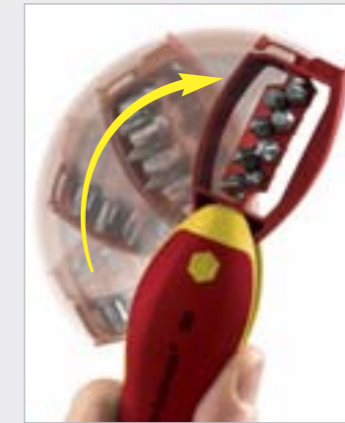

**Wiha magazine bit holder.**

- Innovative bit removal function
- Extremely handy & compact
- Suitable for all current connection types

## Magazine bit holder 1/4", magnetic.



**38090201** Magazine bit holder, magnetic, 1/4".

Blade: High grade chrome-vanadium steel, through hardened.  
Casing spray-coated directly onto the blade.

Handle: Ergonomic Wiha SoftFinish® multi-component handle with roll-off protection.

Bit holder: Stainless steel with strong magnet.

Suitable for: DIN 3126, ISO 1173, style D 6.3.

Bits: 25 mm Standard bits.

Application: The alternative to a screwdriver set.  
Eight drive shapes in one screwdriver.

Order-No.	Series			
33005 7	38090201			5
Ⓛ	7010 Z	4.5x25	6.5x25	
⊕	7011 Z	PH1x25	PH2x25	PH3x25
⊕	7012 Z	PZ1x25	PZ2x25	PZ3x25

## Blister packed. Display.

**SB 38090201** Magazine bit holder, magnetic, 1/4".  
Blister packed.

Order-No.	Series			
33006 4	SB 38090201			5
Ⓛ	7010 Z	4.5x25	6.5x25	
⊕	7011 Z	PH1x25	PH2x25	PH3x25
⊕	7012 Z	PZ1x25	PZ2x25	PZ3x25

**38090201 VH** Magazine bit holder, display, 10 pcs.  
Sales display made of card with integrated rear panel.

Order-No.	Content	
33248 8	10 x 38090201	1