

Galaxy-1000

- 1000 Lumens
- 10m Beam Distance
- 2 Light Modes
- Max Run Time 3hrs 20mins


- Rechargeable Li-ion LED floodlights
- 1,000 lumens
- Fold flat design for compact storage
- 10 metre flood beam
- High impact ABS housing and shatterproof polycarbonate lens
- 2 light settings: high and low

Powered by Rechargeable **LI-ION** Technology



Specifications

Light Output (Lumens)	1000 500
Light Beam	10 Metre beam distance
Battery	Li-ion (18650), 1800mAh 7.4V
Charge Time	4hrs
Product Weight	539g
Dimensions (mm)	(L) 193.5 (W) 230.4 (D) 63.6mm
Boxed Size (mm)	(L) 350 (W) 220 (D) 70mm
Power Modes	High and Low
Runtime	Full 1h40m, half 3h20m
Part Number:	NSGALAXY1000
Part Number Tripod:	SPTRIPOD1.7

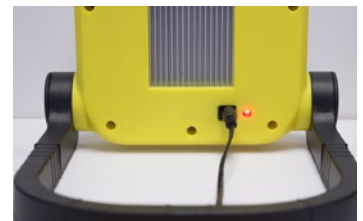

Galaxy-1000 battery charging indicator

Supplied with:
230V AC
Vehicle charger

360° 360° handle and stand



Optional Tripod

Optional extras:
1.7m Tripod