


---

Item no.: 264-724  
Product description: 4-CONDUCTOR MINIATURE THROUGH TERMINAL BLOCK;  
CENTRE MARKING; SUITABLE FOR EX I APPLICATIONS;  
for DIN 15 rail; FRONT-ENTRY; CAGE CLAMP®CONNECTION

---

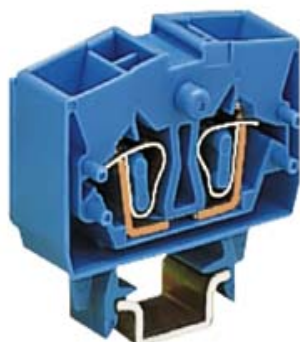

Packing unit 100 pieces

|                                       |                           |
|---------------------------------------|---------------------------|
| Product group                         | 9 (Std Chassis Mt Blocks) |
| Cross section from [mm <sup>2</sup> ] | 0,08 mm <sup>2</sup>      |
| Cross section to [mm <sup>2</sup> ]   | 2,5 mm <sup>2</sup>       |
| Cross section from [AWG]              | 28 AWG                    |
| Cross section to [AWG]                | 12 AWG                    |
| Connection method                     | CAGE CLAMP®CONNECTION     |
| Number of strands                     | 2                         |
| Measured voltage EN                   | 800 V                     |
| Measured shock voltage                | 8 kV                      |
| Pollution degree                      | 3                         |
| Current intensity EN                  | 24 A                      |
| Weight                                | 6 g                       |
| Color                                 | blue                      |
| Wiring type                           | Front-entry               |
| No. of connection Points              | 4                         |
| No. of potentials                     | 1                         |
| Height                                | 24,5 mm                   |
| Height                                | 0,96 in                   |
| Width                                 | 10 mm                     |
| Width                                 | 0,394 in                  |
| Depth                                 | 32 mm                     |
| Depth                                 | 1,26 in                   |



|                   |         |
|-------------------|---------|
| Strip length from | 8 mm    |
| Strip length to   | 9 mm    |
| Strip length      | 0,33 in |



| Item number | Admission office | Approval no.      | Voltage [V] | Current [A] | Cross section [ mm <sup>2</sup> ] |
|-------------|------------------|-------------------|-------------|-------------|-----------------------------------|
| 264-724     | ABS              | 04-HG476174-PDA   | 800         | 24          | 2,5                               |
| 264-724     | BV               | 07436/C0          |             |             | 0,08-2,5                          |
| 264-724     | CCA              | NL5704            | 800         |             | 2,5                               |
| 264-724     | CSA              | 18677-23          | 600         | 20          | 26-12                             |
| 264-724     | DNV              | E7569             | 800         | 24          | 2,5                               |
| 264-724     | GL               | 17295-00HH        | 800         | 24          | 4                                 |
| 264-724     | KEMA             | 2079570.01        | 800         | 24          | 2,5                               |
| 264-724     | KR               | HMB05880-EL002    | 800         | 24          |                                   |
| 264-724     | LR               | 92/20242(E5)      | 800         | 24          | 2,5                               |
| 264-724     | PRS              | TE/1718/880590/08 | 800         |             | 2,5                               |
| 264-724     | RMR              | 11130002          | 800         | 24          | 2,5                               |
| 264-724     | UR               | E45172            | 600         | 20          | 28-12                             |

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected