


LED Flexi Tape Tuneable White

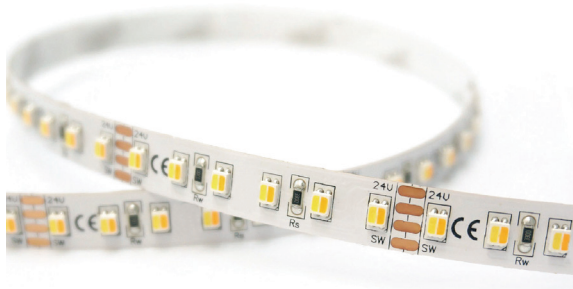

Key Features:



- Tuneable White from 3000K ~ 6000K
- High CRI ≥80
- Supplied in 5M reels cuttable every 50mm
- 60 and 120 LEDs per metre
- Fitted with 3M Adhesive tape
- 3 years warranty

TUNEABLE WHITE SPECIFICATION

| | | |
|---------------------|-------------------------|--------------------------|
| Model No. | TN-55-27-1-60-F10-20-FP | TN-55-27-2-120-F10-20-FP |
| Voltage | 12VDC | 24Vdc |
| Power Consumption | 9.6W/M | 19.2W/M |
| LED Qty | 60 per mtr | 120 per mtr |
| LED pitch | 16.7mm | 16.67mm |
| Beam Angle | 120° | 120° |
| Cutttable | Every 50mm | Every 100mm |
| Colour Target | 3000K ~ 6000K | 3000K ~ 6000K |
| Luminous Flux | 750lm/M | 1500lm/M |
| IP Rating | IP20 | IP20 |
| Back Adhesive | 3M adhesive tape | 3M adhesive tape |
| Working temperature | -20°C ~ +40°C | -20°C ~ +40°C |
| Humidity | 40% ~ 70% RH | 40% ~ 70% RH |
| Dimensions | 5000 x 10 x 2.3mm | 5000 x 10 x 2.3mm |



Mechanical

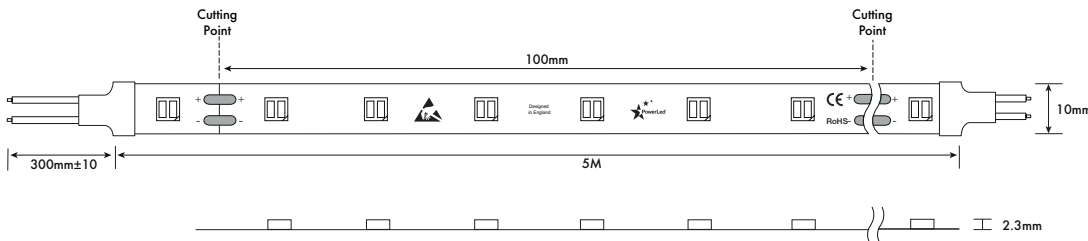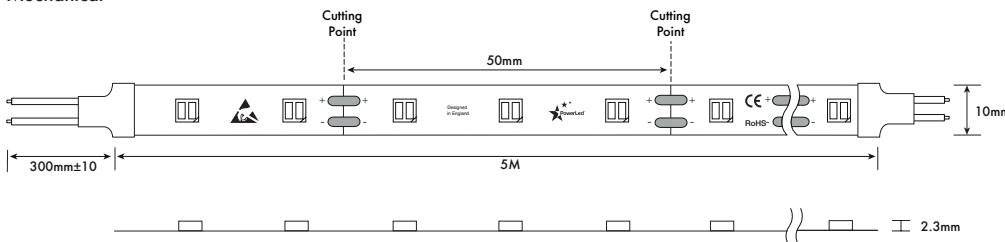

PowerLed (UK) Ltd
Orion House
Calleva Park
Aldermaston
Berkshire
RG7 8SN


Contact:
Tel: 0118 9703856
enquiries@powerled.uk.com
www.powerled.uk.com



LED Flexi Tape Tuneable White



Photometrics

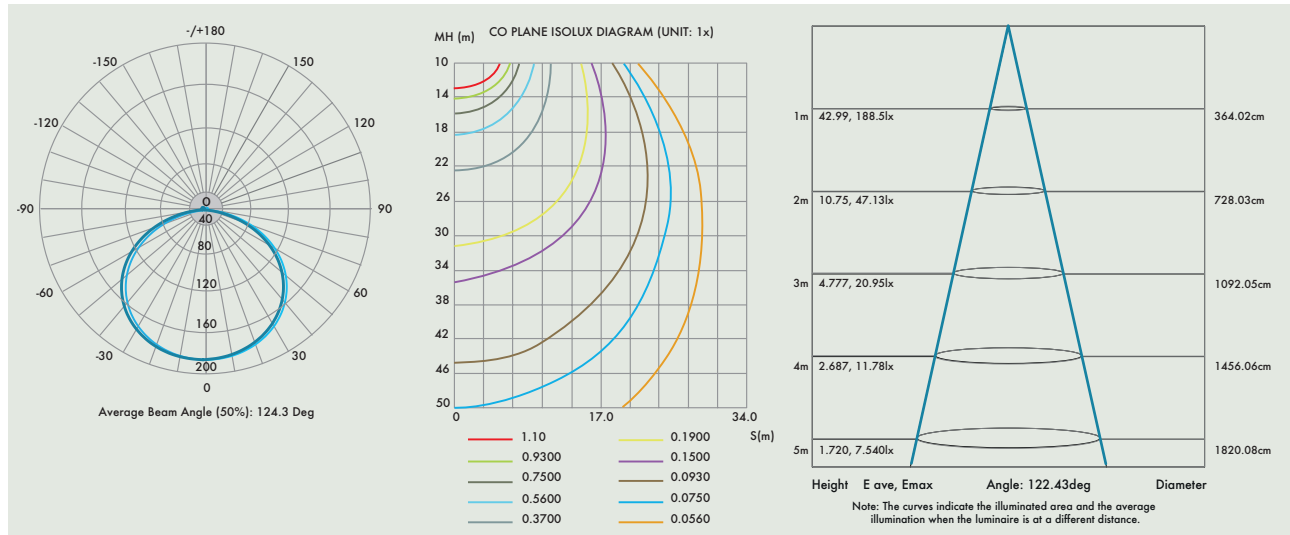


Also Available

CCT-RF-RCX



CCT-RF-3x5A

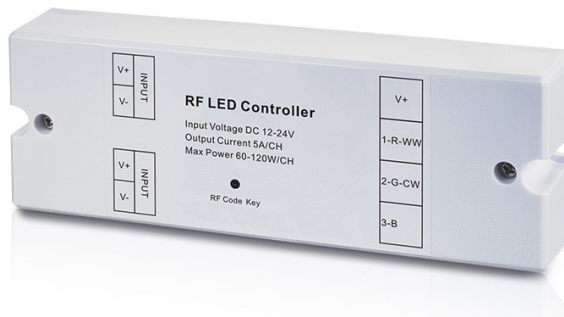

Key Features:

- Suitable for indoor LED lighting
- User-friendly interface, easy and simple operation
- Full Tone Adjustment
- Dimming Control
- Simple Modes
- Smooth Tone Control Curve
- Operating Frequency 434MHz/868MHz/915MHz