


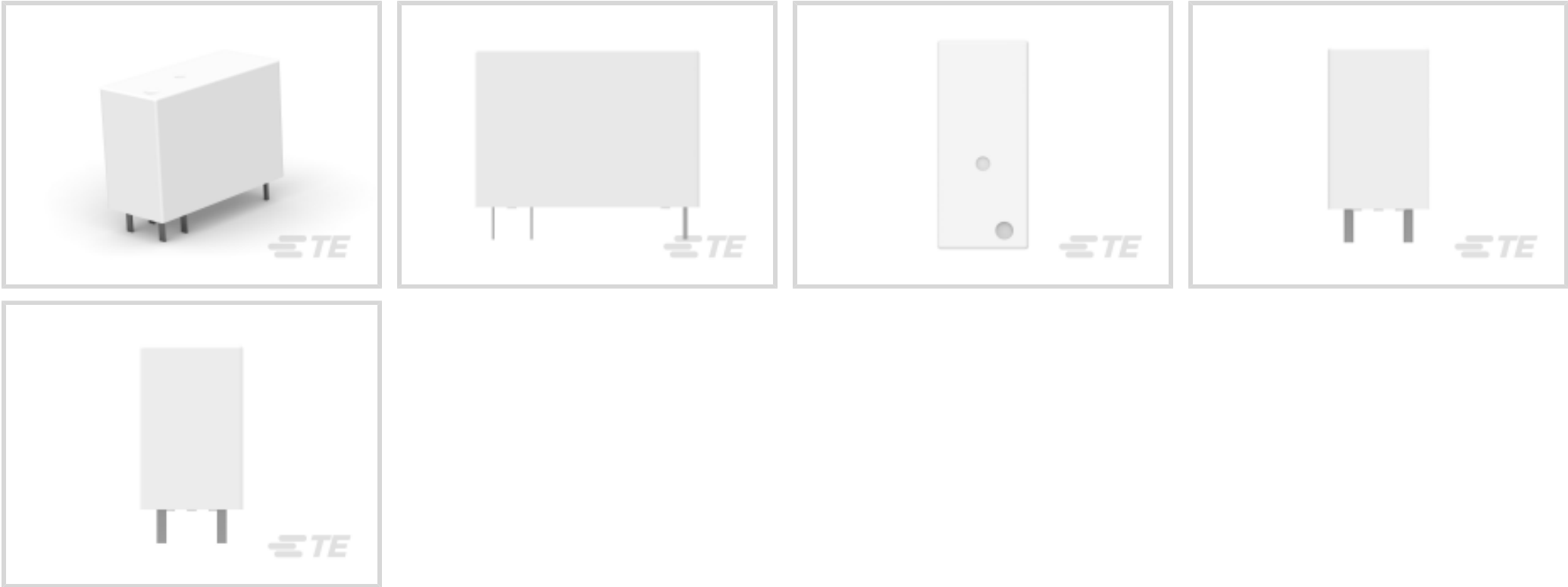

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	有害物质含量符合标准要求 No Restricted Substance(s) Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2025 (250) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Wave solder capable to 265°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Customers Also Bought



TE Part #6-1419128-6
OJE-SS-124HMF,F000

TE Part #4-1419144-7
OJE-SH-112HMF,F095

TE Part #2-2271101-1
SCSI .050 REC ASS'Y 20P PB-FRE

TE Part #5-2271101-1
SCSI .050 REC ASS'Y 50P PB-FREE

TE Part #2271608-1
AMPMODU, PIN HDR, 2.0PITCH,
4ROW, TH,56P

TE Part #1461868-5
OZ-SS-112LM1F,000

TE Part #1419126-5
SDT-SH-112DM,000

TE Part #1-1721260-1
OJ-SH-112LMH2

TE Part #2271609-1
AMPMODU, REC HDR, 4ROW,TH, 56P

TE Part #2393479-1
DYNAMIC D3950 6PI RECEPTACLE
ASSEMBLY

Documents

Product Drawings

OZ-SS-124LM1,200

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_2-1440002-9_J.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_2-1440002-9_J.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_2-1440002-9_J.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages



OZ_OZT Series Relay Data Sheet - English

English

Product Specifications

Product Specification

Japanese

Definitions General Purpose Relays

English